

wiring accessories



7300 60 7300 65 6781 38



7300 70 8330 65 7300 34



8330 93



5721 17 5720 78

 
Pack	Cat. Nos.
1	MP820329
1	MP820339

Back boxes

Socket back boxes

Material : pre-galvanised steel
1 gang back box

2 gang back box



Pack	Cat. Nos.	
	White	Brushed stainless steel
10 / 1	7300 60	8330 60
5 / 1	7300 70	8330 70
10 / 1	7300 65	8330 65
5 / 1	7300 75	8330 75
1	6781 34	8330 86
1	6781 38	8330 98
10 / 1	7300 34	8330 34
10 / 1	7300 36	8330 37 ¹


Synergy sockets (monobloc)

Double pole switched socket outlets 13 A - 250 V

Conform to BS 1363 - Part 2 : 1995

10 / 1 1 gang - switched

5 / 1 2 gang - switched

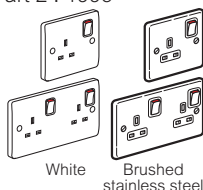


Unswitched socket outlets 13 A - 250 V

Conform to BS 1363 - Part 2 : 1995

10 / 1 1 gang - unswitched

5 / 1 2 gang - unswitched

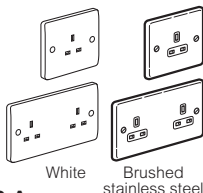


RCD socket outlets 13 A - 250 V ELR - DP 30 mA - passive

Conform to BS 7288 : 1990 and BS 1363 - Part 2 : 1995
Maximum operating current 16 A
With "Test and reset" button
Does not trip in the event of power failure
Suitable in applications where automatic restoration of supply is required

1 1 gang - DP

1 2 gang - DP

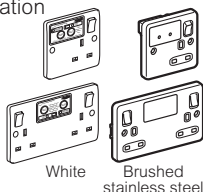


Fused connection units 13 A - 250 V

Conform to BS 1363 - Part 4 : 1995

10 / 1 1 gang - Switched, DP without cord outlet

10 / 1 1 gang - Switched, DP with cord outlet

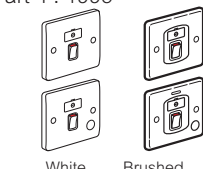

1: With blue 'power on' LED indicator

Pack	Cat. Nos.	
	White	Brushed stainless steel
10 / 1	7300 91	8330 91
10 / 1	7300 92	8330 92
10 / 1	7300 93	8330 93
10 / 1	7300 94	8330 94

Carrier plates for Arteor modules


No additional support frame required

1 gang - 1 module plate

1 gang - 2 module plate

2 gang - 3 module plate

2 gang - 4 module plate

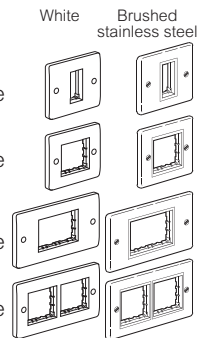

Pack	Cat. Nos.	
	White	Magnesium
5	5721 30	5726 30
5	5724 67	
10	5720 21	5725 21
10	5721 17	5726 17
5 / 1	5720 78	5725 78
1	5720 96	5725 96
10	5723 23	5728 23
10	5723 22	5728 22
10	5723 04	5728 04
10	5723 03	5728 03

Arteor modules

British standard 13 A socket outlets

Conform to BS 1363 - Part 2
ASTA license
3 modules - 2P + E switched

3 modules - 2P + E switched
dedicated non-standard pin

International standards socket outlets

Not suitable for domestic installations in the UK or Ireland
French - 10/16 A
2 modules - 2P + E
shuttered for child safety
American - 15 A - 127 V
2 modules - 2P + E

Double USB sockets - 5 V - 2400 mA

For fast-charging telephones, smartphones, MP3/MP4 players and tablet PC
2 modules

HDMI audio and video sockets

Preconnected
Equipped with a 15 cm cord
1 module

RJ45 data sockets

Rapid connection sockets
No tool required
CAT 6 - STP - 9 contacts, shielded folded metal. 1 module
CAT 6 - FTP - 9 contacts. 1 module
CAT 5e - FTP - 9 contacts. 1 module
CAT 5e - UTP - 8 contacts. 1 module

For complete range of wiring accessories
see **Legrand's website**
www.legrand.co.uk

