


commercial floor trunking systems

flush floor trunking

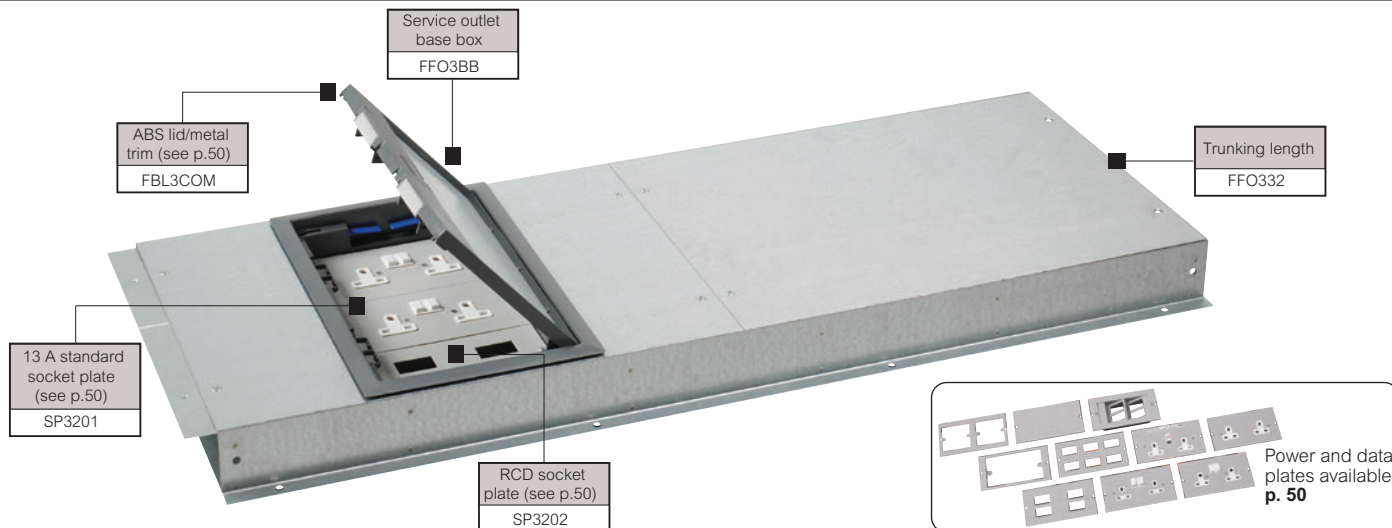

Screed floor outlet boxes selection chart p. 48-49
Dimensions and technical information p. 53
Installation details p. 55

Body and lid manufactured from pre-galvanised sheet steel to BS EN 10346
 Standard lengths : trunking 2.0 m, lid 0.5 m
 Standard lid thickness : 2.5 mm
 Each 2 m length is fitted with 4 x 500 mm long lids and supplied complete with all necessary connectors and screws
 Trunking to floor fixings not supplied
 A service outlet floor box can be fitted at each lid position

Pack	Cat. Nos.	Flush floor trunking	
1	3 comp FFO332 4 comp FFO342	Trunking length – 2 m 370 x 65 mm	
1	FFO330	Spare connector set 370 x 65 mm	
1	3 comp FFO3311 4 comp FFO3411	90° riser bend Supplied with screeding cover Provides conduit entry with 20 mm knockouts 370 x 65 mm	
1	3 comp FFOS3SK6 4 comp FFOS4SK6	Back entry skirting adaptor 370 x 65 – 150 mm high skirting 370 x 65 – 200 mm high skirting	
1	FFOS3SK8 FFOS4SK8		
1	3 comp FFOT332T 4 comp FFOT342T	Cable trunking adaptor 370 x 65 mm To complete the Cat. No. specify : T = standard cable trunking Cat. No. Example : FFOT 332 MGR623C	

Pack	Cat. Nos.	Flush floor trunking (continued)	
1	FFO3312	End cap 370 x 65 mm	
1	3 comp FFO3313 4 comp FFO3413	Junction box Supplied with connections and blanking plates Can be configured as a fourway, tee, bend or straight through connector box 370 x 65 mm	
1	3 comp FFO3BB 4 comp FFO4BB	Service outlet base boxes Service outlet base boxes are supplied fitted into a 500 mm long cover To complete the system, the outlet base box requires outlet plates, lid and trim Outlet plates, lids and trims ordered separately, (see p. 50)	

Flush floor trunking can be supplied in widths and depths greater than 370 x 65 mm to special order
Contact us on +44 (0) 370 608 9020

All trims for service outlet boxes can be ABS, stainless steel, brass or powder coated any colour **p. 50**