


commercial floor trunking systems

underfloor duct

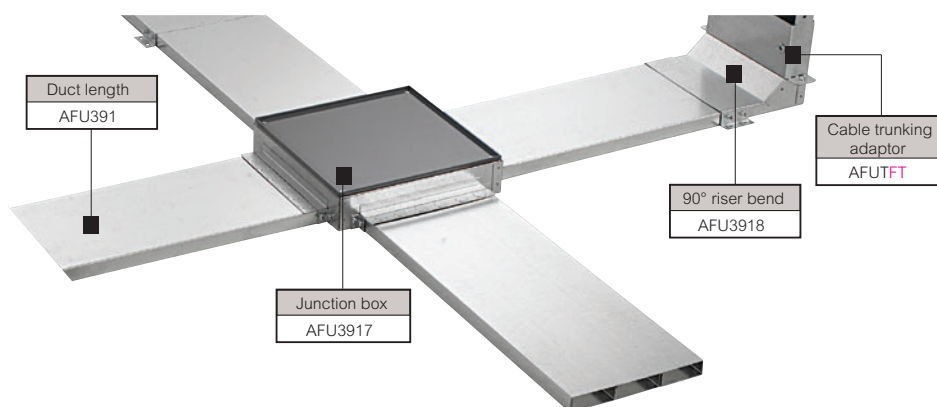

Screed floor outlet boxes selection chart **p. 48-49**
 Dimensions and technical information **p. 54**
 Installation details **p. 55**

Body and lid manufactured from pre-galvanised sheet steel to BS EN 10346
 Standard length : 2.0 m. Standard lid thickness : 1.0 mm
 Each 2 m length is supplied with 2 saddle clamps and screws
 Duct to floor fixings are not supplied

Pack	Cat. Nos.	Underfloor duct	
		Duct length – 2 m	
1	2 comp AFU261	3 comp AFU361	
1	AFU265	AFU365	
1		AFU391	
1		AFU395	
1		AFU311	
1		AFU315	
		Spare saddle clamp	
1	AFU2612	150 x 25 mm	
1	AFU2652	150 x 38 mm	
1	AFU3912	225 x 25 mm	
1	AFU3952	225 x 38 mm	
1	AFU3112	300 x 25 mm	
1	AFU3152	300 x 38 mm	
		90° flat bend	
1	2 comp AFU2613	3 comp AFU3613	
1	AFU2653	AFU3653	
1		AFU3913	
1		AFU3953	
1		AFU3113	
1		AFU3153	
		90° riser bend	
		Supplied with screeding cover Provides conduit entry with 20 mm knockouts	
1	2 comp AFU2618	3 comp AFU3618	
1	AFU2654	AFU3654	
1		AFU3918	
1		AFU3954	
1		AFU3118	
1		AFU3154	
		Back entry skirting adaptor	
1	AFUSFSK S	To complete the Cat. No. specify : F = underfloor duct size code S = skirting trunking height in inches Example : AFUS 391 SK6	
		Cable trunking adaptor	
1	AFUTFT	Supplied with turnbuckle fix lid To complete the Cat. No. specify : F = underfloor duct size code T = standard cable trunking Cat. No. Example : AFUT 395 MGR623C	

Pack	Cat. Nos.	Underfloor duct (continued)	
		End cap	
1	AFU2615	150 x 25 mm	
1	AFU2655	150 x 38 mm	
1	AFU3915	225 x 25 mm	
1	AFU3955	225 x 38 mm	
1	AFU3115	300 x 25 mm	
1	AFU3155	300 x 38 mm	
		Junction box	
		Can be configured as a fourway, tee, bend or straight through connector box When using with a conduit system, select junction box depending on conduit size For 20 mm conduit use junction box that would suit a 25 mm ducting For 25 mm conduit use junction box that would suit a 38 mm ducting	
		To suit screed 65 mm to 80 mm deep	
1	2 comp AFU2617	3 comp AFU3617	
1	AFU2657	AFU3917	
1		AFU3117	
		300 x 25 mm	
		To suit screed 75 mm to 90 mm deep	
1	AFU2656	AFU3656	150 x 38 mm
1		AFU3956	225 x 38 mm
1		AFU3156	300 x 38 mm

Underfloor duct can be supplied in other widths, depths and compartment configurations to special order
Contact us on +44 (0) 370 608 9020

