
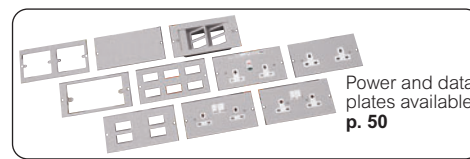


# commercial floor trunking systems

## underfloor duct (continued)

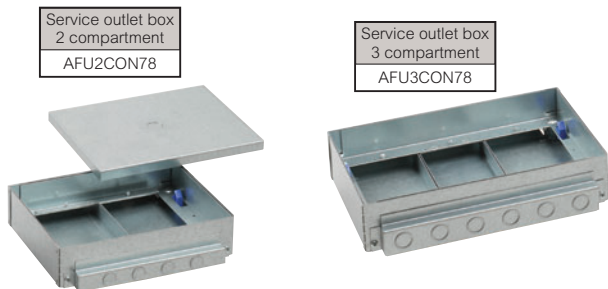

Sced floor outlet boxes selection chart p. 48-49  
 Dimensions and technical information p. 54  
 Installation details p. 55

Body and lid manufactured from pre-galvanised sheet steel to BS EN 10346  
 Standard length : 2.0 m. Standard lid thickness : 1.0 mm  
 Each 2 m length is supplied with 2 saddle clamps and screws  
 Duct to floor fixings are not supplied

Pack	Cat. Nos.	In-screed service outlet base boxes
		Service outlet base boxes are supplied empty To complete the system, the outlet base box requires outlet plates, lid and trim Outlet plates, lids and trims ordered separately, (see p. 50) Use a 2 or 4 compartment service outlet box with 2 compartment duct 2 compartment box can only be used with 150 mm wide ducting
		<b>To fit 25 mm deep ducting</b>
1	AFU2BB78	To suit screed 65 mm to 80 mm deep 2 compartment to suit 25 mm shallow ducting
1	AFU3BB78	3 compartment to suit 25 mm shallow ducting
1	AFU4BB78	4 compartment to suit 25 mm shallow ducting
		<b>To fit 38 mm deep ducting</b>
1	AFU2BB90	To suit screed 75 mm to 90 mm deep 2 compartment box to suit 38 mm deep ducting
1	AFU3BB90	3 compartment box to suit 38 mm deep ducting
1	AFU4BB90	4 compartment box to suit 38 mm deep ducting

Pack	Cat. Nos.	In-screed service outlet base boxes (continued)
		<b>20 mm conduit fed</b>
1	AFU1CON78	To suit screed 65 mm to 80 mm deep 1 compartment box to suit 20 mm conduit
1	AFU2CON78	2 compartment box to suit 20 mm conduit
1	AFU3CON78	3 compartment box to suit 20 mm conduit
1	AFU4CON78	4 compartment box to suit 20 mm conduit
		<b>25 mm conduit fed</b>
1	AFU1CON90	To suit screed 75 mm to 90 mm deep 1 compartment box to suit 25 mm conduit
1	AFU2CON90	2 compartment box to suit 25 mm conduit
1	AFU3CON90	3 compartment box to suit 25 mm conduit
1	AFU4CON90	4 compartment box to suit 25 mm conduit



All trims for service outlet boxes can be ABS, stainless steel, brass or powder coated any colour p. 50

