


industrial floor trunking systems

chequer plate floor trunking

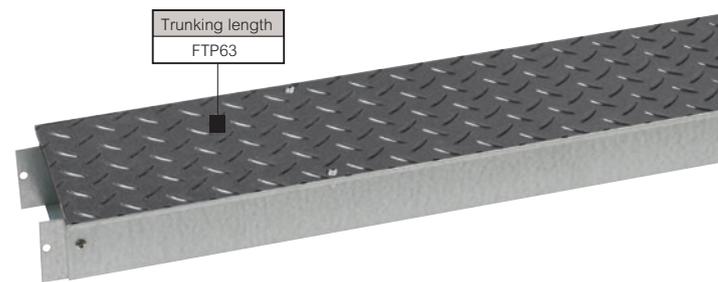


Dimensions and technical information **opposite**
Installation details **p. 55**

Body manufactured from pre-galvanised sheet steel to BS EN 10346
Lid manufactured from mild steel, powder coated grey 18B25
Other colours available to special order
Standard lengths : body 2.0 m, lid 1.0 m
Standard lid thickness : 6.5 mm
Chequer plate floor trunking is available in single compartment as standard complete with lid, all necessary connectors and screws
Internal dividers are fitted on all trunking lengths 225 mm and above to provide lid support
Service outlet boxes are not available for this range

Pack	Cat. Nos.	Chequer plate floor trunking	
		Trunking length – 2 m	
1	FTP42	100 x 50 mm	
1	FTP63	150 x 75 mm	
1	FTP124	300 x 100 mm	
		90° riser bend	
		Supplied with screeding cover Provides conduit entry with 20 mm knockouts	
1	FTPRB42	100 x 50 mm	
1	FTPRB63	150 x 75 mm	
1	FTPRB124	300 x 100 mm	
		End stop	
1	FTPEB42	100 x 50 mm	
1	FTPEB63	150 x 75 mm	
1	FTPEB124	300 x 100 mm	
		Junction box	
		Supplied with connectors and blanking plates To be configured as a fourway, tee, bend or straight through connector box	
1	FTPI42	100 x 50 mm	
1	FTPI63	150 x 75 mm	
1	FTPI124	300 x 100 mm	


Chequer plate floor trunking can be supplied in other widths, depths and compartment configurations to special order
Contact us on +44 (0) 370 608 9020

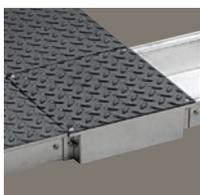

industrial floor trunking systems

dimensions and technical information

 Chequer plate floor trunking




W¹ = Overall trunking width
D = Overall trunking depth
w² = Overall width including trunking lid

Cat. No.	W ¹	D	w ²
FTP42	100	50	150
FTP63	150	75	200
FTP124	300	100	350

90° riser bends

Duct depth	A
50	50
75	75
100	100

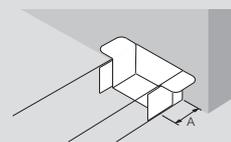

Junction box

Trunking width	A
100	150
150	200
300	350

