

# Marina wall mounting enclosures

Polyester (GRP) IP 66 - IK 10



0362 56



0362 76



0362 63 + plinth Cat. No. 0362 92  
+ roof Cat. No. 0362 95




0362 55 + wall brackets Cat. No. 0364 09

Enclosure and equipment selection chart **p. 6-7**  
Technical information and dimensions **p. 17-18**  
Equipment **p. 21-29**

Grey RAL 7035  
IP 66 according to IEC EN 60529  
IK 10 according to IEC EN 62262 (EN 50102)  
Class II insulation for final assembly according to IEC EN 60439-1  
Glass fibre reinforced polyester (GRP) enclosures  
Self extinguishing at 960 °C according to IEC EN 60695-2-11  
Designed for corrosive environments  
Reversible door, 180° opening<sup>1</sup>  
2 x double bar locks<sup>1</sup>  
Captive stainless steel hinge pins<sup>1</sup>  
Mounting plate/equipment can be fixed directly to the rear of the enclosure  
Accepts partial plate from 500 x 400 x 200 mm and/or rails<sup>1</sup>  
Optional depth adjustment kit (Cat. No. 0362 42) available for enclosures 400 mm high and above  
For wall mounting, wall mounting brackets must be ordered separately

Pack	Cat. Nos.	GRP enclosures					
<b>Plain door</b>							
External dimensions (mm)							
		Height	Width	Depth		Weight (kg)	
1	0362 50	300	220	160		1.75	
1	0362 51	400	300	206		3.7	
1	0362 52	500	400	206		5.1	
1	0362 55	610	400	257		6.4	
1	0362 56	720	510	250		11.2	
1	0362 61	820	610	300		15.2	
1	0362 63	1020	810	300		21.8	
1	0362 64	1220	810	300		25.0	
<b>Glazed door with tinted glass window</b>							
External dimensions (mm)							
		Height	Width	Depth	Window (mm)	Weight (kg)	
					Height	Width	
1	0362 71	400	300	206	235	145	4.0
1	0362 72	500	400	206	335	245	5.6
1	0362 75	610	400	257	463	245	7.0
1	0362 76	720	510	250	570	272	12.3
1	0362 81	820	610	300	672	372	16.7

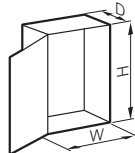

Pack	Cat. Nos.	Fixing accessories	
		IP 66 maintained	
		<b>Wall mounting brackets</b>	
		Set of 4, supplied with screws	
		For enclosures	
		Height (mm)	Max. load (kg)
1	0364 08	300	100
1	0364 09	400 to 1200	150
		<b>Rear with threaded rod</b>	
		M8 for enclosures height ≥ 400 mm	
		Mounting at back of enclosures	
		<b>Accessories</b>	
1	0362 42	Depth adjustment kit for enclosures ≥ 200 mm	
		4 fixings complete with screws	



<b>Roofs</b>			
IK 10			
For enclosures (mm)			
		Width	Depth
1	0362 93	500	250
1	0362 94	600	300
1	0362 95	800	300

<b>Plinths</b>			
Height 170 mm			
Front and rear trap door			
Possibility to overlap 2 plinths			
For enclosures (mm)			
		Width	Depth
1	0362 91	600	300
1	0362 92	800	300

Plain and perforated plates **p. 21**  
Modular chassis **p. 23**  
Internal doors **p. 23**  
Sectioned uprights **p. 24**  
Crosspieces **p. 24**  
Locking accessories **p. 26**

1 : Except Cat. No. 0362 50