

equipment and fixing accessories for wall mounting enclosures

Atlantic, Atlantic stainless steel and Marina



Uprights + crosspieces (subject to size)
Pocket Cat. No. 0365 80



0365 81



0367 80



0364 40



0366 44



0347 45



0347 50



0016 90



0016 91

Technical information and dimensions p. 25

Lina 25 sectioned uprights

Set of 2 sectioned uprights

For dimensions p. 25

Pack	Cat. Nos.	For enclosures height (mm)	Length of uprights (mm)	Thickness (mm)	Profile
5	0361 50	300	237	2.5	
5	0361 51	400	337	2.5	
5	0361 52	500	437	2.5	
5	0361 53	600	537	2.5	
5	0361 54	700	637	2.5	
5	0361 55	800	737	2.5	
5	0361 56	1000	937	2.5	
5	0361 58	1200	1137	2.5	

Lina 25 crosspieces

Crosspieces ready to assemble (excluding fixings)


For dimensions p. 25

Pack	Cat. Nos.	For enclosures width (mm)	Crosspiece length (mm)
10	0367 80	300	243
10	0367 81	400	343
10	0367 82	500	443
10	0367 83	600	543
10	0367 84	800	743

Rails

2 m length
For dimensions p. 25

10	0374 02	EN 60715
10	0374 04	EN 60715, depth 7.5 mm
10	0374 07	Symmetrical, depth 15 mm

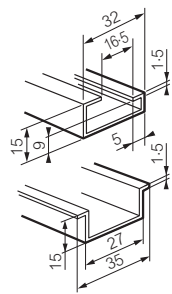

45° mounting bracket

Set of 2 supports for tilting a rail at an angle of 45°
Supplied with 4 x M6 screws, nuts and washers

10	0394 49	
----	---------	--

Fixing accessories

For Lina 25 perforated plates

Supplied without screws

100	0364 40	Clip nuts for M4 screw
100	0364 41	Clip nuts for M5 screw
100	0364 42	Clip nuts for M6 screw

For Lina 12.5 perforated plates

Insulated plastic rivets Ø 6 mm for 6 mm holes
Self piercing tapping hex head screws 4.8 x 16 mm for Ø 3.3 mm holes
Plastic insulating cap for above

500	0366 44 ¹	
100	0347 45	
200	0347 50	

Lina perforated plates p. 21

Fixing accessories (continued)

Pack	Cat. Nos.	Description	Image																				
20	0364 66 ¹	Adaptor For mounting on rail equipment fitting on rail Width 17 mm Increase equipment height of 6 mm																					
100	0364 78	For rails EN 60715 ,																					
100	0364 79	For M4 screw																					
10	0044 16	For rails EN 60715 Claw width 10 mm Threaded hole for M4 screw																					
10	0044 17	Claw width 17.5 mm Smooth hole Ø 3.8 mm Supplied with fixing screw Ø 3.5 mm Length 13 mm																					
100	0374 39	Claw width 35 mm Holes for M4 and M6 screws																					
40	0364 69	Fixomega for M4 screw																					
100	0347 46	On plain plates CBL Z 5.5 x 16 PZ No 3 self-tapping screw																					
100	0347 47	CBL Z 5.5 x 19 self-drilling tapping screw																					
20	0364 50	Cage nuts For mounting on square perforation 8.3 x 8.3 mm																					
20	0364 51	M4																					
20	0364 52	M5																					
50	0367 75	HF screw with contact washer M 6-10 HF screws with contact washers																					
10	0373 88	Copper bars Copper bars with tapped holes																					
10	0373 89	<table border="1"> <thead> <tr> <th>Cross-section (mm)</th> <th>Max. intensity allowed (A)</th> <th colspan="2">Tapped holes</th> <th>Length (mm)</th> </tr> <tr> <th></th> <th></th> <th>Ø mm</th> <th>Pitch</th> <th></th> </tr> </thead> <tbody> <tr> <td>12 x 2</td> <td>110</td> <td>M5</td> <td>18</td> <td>990</td> </tr> <tr> <td>12 x 4</td> <td>160</td> <td>M5</td> <td>18</td> <td>990</td> </tr> </tbody> </table>		Cross-section (mm)	Max. intensity allowed (A)	Tapped holes		Length (mm)			Ø mm	Pitch		12 x 2	110	M5	18	990	12 x 4	160	M5	18	990
Cross-section (mm)	Max. intensity allowed (A)	Tapped holes		Length (mm)																			
		Ø mm	Pitch																				
12 x 2	110	M5	18	990																			
12 x 4	160	M5	18	990																			
100	0373 65	Connectors for bars with tapped holes 1 or 2 conductor from 1.5 to 10 mm ² (supplied with Ø5 mm screws)																					
20	0365 80	Self-adhesive document pockets RAL 7035																					
20	0365 81	<table border="1"> <thead> <tr> <th colspan="2">External dimensions (mm)</th> <th colspan="2">Internal dimensions (mm)</th> </tr> <tr> <th>Width x Height</th> <th></th> <th>Width x Height x Depth</th> <th></th> </tr> </thead> <tbody> <tr> <td>340 x 235</td> <td></td> <td>310 x 200 x 18</td> <td></td> </tr> <tr> <td>260 x 165</td> <td></td> <td>230 x 130 x 18</td> <td></td> </tr> </tbody> </table>		External dimensions (mm)		Internal dimensions (mm)		Width x Height		Width x Height x Depth		340 x 235		310 x 200 x 18		260 x 165		230 x 130 x 18					
External dimensions (mm)		Internal dimensions (mm)																					
Width x Height		Width x Height x Depth																					
340 x 235		310 x 200 x 18																					
260 x 165		230 x 130 x 18																					
5	0016 91	Modular device accessories Protective terminal shield Light grey. Ensures the protection of wiring and terminals in modular mechanisms fitted in enclosures (Atlantic or Marina) Width 45 mm, Length 1 m Clips on to support 0016 90 (below)																					
10	0016 90	Insulated support For protective terminal shield Clips on to rail EN 60715																					
10	0049 96	Self-adhesive label holder Width : 16 mm Width available for marking : 12 mm Length : 430 mm (24 modules)																					

¹ : Can also be used on Lina 25 perforated plates