


Plexo³ weatherproof enclosures and accessories

IP 65 - IK 09

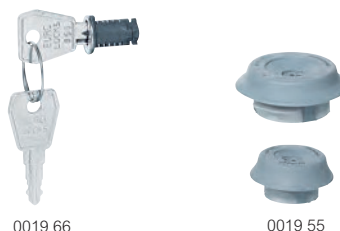

Technical information and dimensions **p. 32**

IP 65 - IK 09 - Class II
 Self-extinguishing : resistance to incandescent wire 650 °C
 Conform to EN 60439-3
 Door and enclosure fully reversible
 Removable chassis and faceplates from 2 row versions up
 2 position rail for modular products and moulded cases
 Spacing between rails 150 mm
 Can be fitted with perforated plates and solid faceplates for mounting non-modular products
 Lockable door handle, sealable cover and faceplate
 Shock-resistant polystyrene material
 Box colour light grey L750A, cover colour dark grey R746A
 Supplied with earth and neutral terminal blocks (except Cat. No. 6019 32)

Pack	Cat. Nos.	Enclosures 2 to 8 modules per row	
		Number of rows	Number of modules
1	6019 32	1	2 (+1)
1	6019 74	1	4
1	6019 76	1	6
1	6019 78	1	8

Pack	Cat. Nos.	Enclosures 12 modules per row	
		Number of rows	Number of modules
1	6019 81	1	12
1	6019 82	2	24
1	6019 83	3	36

Pack	Cat. Nos.	Enclosures 18 modules per row	
		Number of rows	Number of modules
1	6019 85	1	18
1	6019 86	2	36
1	6019 87	3	54
1	6019 88	4	72

Pack	Cat. Nos.	Accessories	
		Installation supports for terminal blocks	
		Set of 2 supports for mounting additional terminal blocks or empty supports for screw terminal blocks into Plexo ³ enclosures	
1	0019 72	For 1 and 2 row enclosures, 12 and 18 modules per row	
1	0019 73	For 3 and 4 row enclosures, 12 and 18 modules per row	
		Key lock	
1	0019 66	N° 850	
		Sealing kit	
1	0019 68	Set of 2 sealable terminal shields for cover and 8 sealable supports for faceplate	
		Wall mounting brackets	
1	0019 69	Set of 4	
		Blanking plates	
20	0019 61	5, separable into modules or 1/2 module Grey R746A	
20	0016 64	Lexic for 18 modules enclosure White	
		Direct piercing end caps	
1	0019 55	Pack consisting of 2 32Ø mm ISO end caps, 5 Ø25 mm ISO end caps and 10 Ø20 mm ISO end caps	
		Plain faceplates	
2	0019 64	For 12 modules enclosure	
2	0019 65	For 18 modules enclosure	
		Perforated plates	
2	0019 62	Allow the DIN rail to be replaced with a Lina 25 plate when integrating non-modular products For 12 modules enclosure Height 150 mm	
2	4018 53	For 18 modules enclosure Height 150 mm	
		ISO M20 cable gland	
25	0980 03	Cable gland IP68	



IP 2X terminal blocks **p. 40**

