

Plexo weatherproof boxes

IP 55 - IK 07




Selection chart **p. 34**
Dimensions **opposite**

IP 55 - IK 07
Grey RAL 7035
Conform to EN 60695-2-1
Polystyrene box and polypropylene cover - halogen free
Temperature rating : -25 °C to +40 °C
Self-extinguishing 650 °C
Membrane glands
Plain cover


| Pack | Cat. Nos. | Weatherproof boxes – round |
|--------------------------------------|-----------|---|
| 5 | 0920 01 | With fixing slots for easy alignment Use 5 mm Ø screws Clip-on cover Nominal internal dimensions : Ø x Depth Ø 60 mm x 40 mm 4 glands |
| 5 | 0920 02 | Ø 70 mm x 45 mm 4 glands |
| Weatherproof boxes – square | | |
| 5 | 0920 05 | With fixing slots for easy alignment Use 5 mm Ø screws Clip-on cover Nominal internal dimensions : Height x Width x Depth 65 x 65 x 40 mm 7 glands |
| 5 | 0920 12 | 80 x 80 x 45 mm 7 glands |
| 5 | 0920 14 | 80 x 80 x 45 mm With pre-cut knockouts |
| Weatherproof boxes – square class II | | |
| 5 | 0920 22 | Mounting by : • either internal fixing points - use 5 mm Ø screws • or at three corners outside the wiring area Use 4 mm Ø screws Provision for anti-tamper seal Cover with 4 x 1/4 turn fixings, indicated I-O, can be retained open during installation Nominal internal dimensions : Height x Width x Depth 105 x 105 x 55 mm 7 glands |
| 5 | 0920 24 | 105 x 105 x 55 mm With pre-cut knockouts |

■ Dimensions (mm)


Cat. No. 0920 01

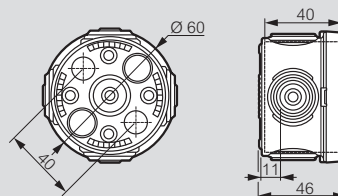


Cat. No. 0920 02

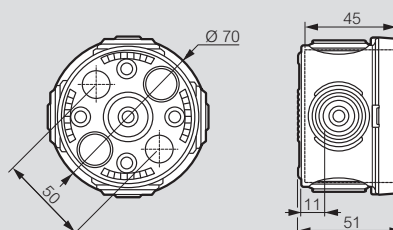

Cat. No. 0920 05

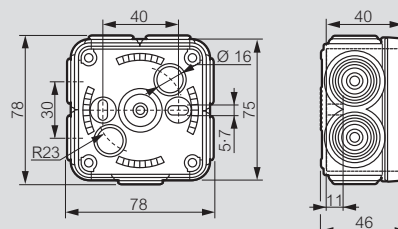

Cat. Nos. 0920 12/14

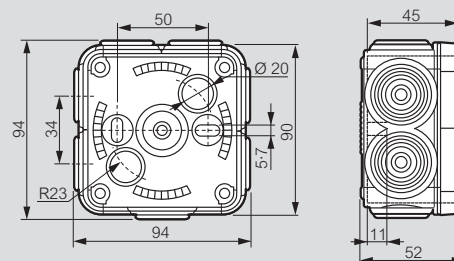

Cat. Nos. 0920 22/24

