


Viking 3 terminal blocks – screw connection

for copper cable

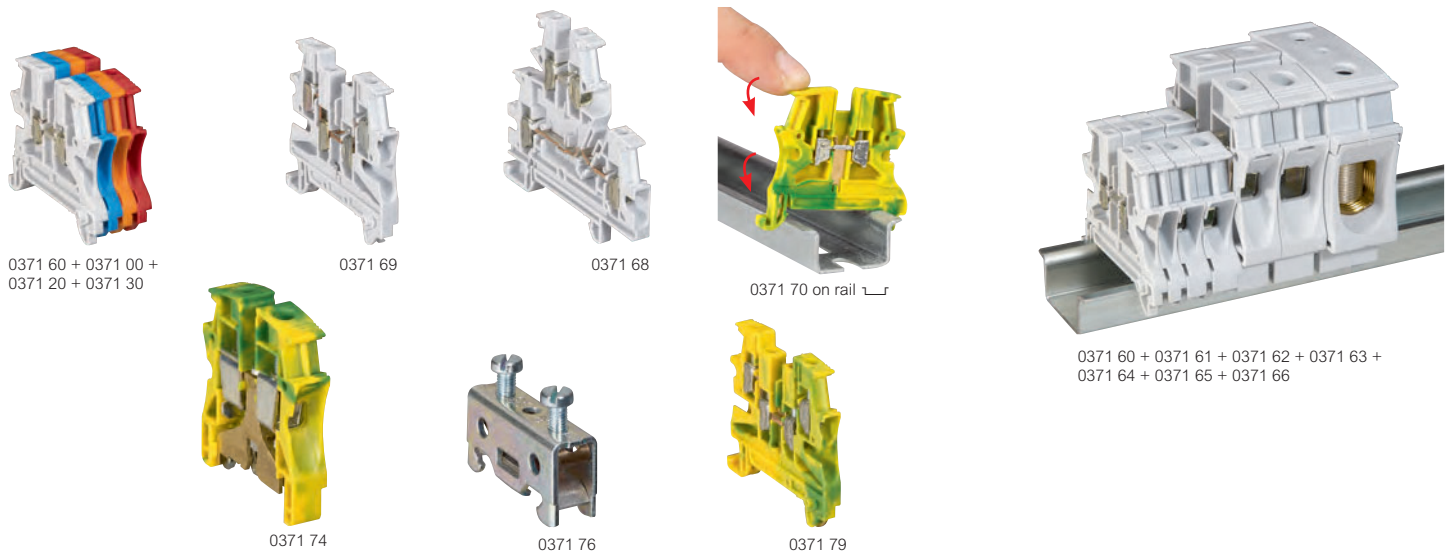

Accessories **p. 58-59**
 Technical characteristics **p. 60-61**

All V2 polyamide UL94 960 °C to IEC EN 60695-2-11
 Compatible with either rigid (0.25 mm² to 95 mm²) or flexible (0.25 mm² to 70 mm²) copper cables
 Facility for 2 bridging combs
 Compatible with rails depth 15 mm and rails EN 60715 depth 7.5 mm and 15 mm
 Range comprises only 2 block heights (2.5 mm² to 10 mm² and 16 mm² to 70 mm²) ensuring a neat installation

Pack	Cat. Nos.	Connection				
		Grey for standard circuit Blue for neutral conductor Orange for circuit not broken by the master isolating device Red for special circuits (safety, protected, etc)				
		1 connection - 1 entry/1 exit				
		Colour	Nominal cross section (mm ²)	Capacity		Width (mm)
				Rigid cable (mm ²)	Flexible cable (mm ²)	
60	0371 60	Grey ●	2.5	0.25 to 4	0.25 to 2.5	5
60	0371 00	Blue ●				
60	0371 20	Orange ●				
60	0371 30	Red ●				
50	0371 61	Grey ●	4	0.25 to 6	0.25 to 4	6
50	0371 01	Blue ●				
50	0371 21	Orange ●				
50	0371 31	Red ●				
40	0371 62	Grey ●	6	0.5 to 10	0.25 to 6	8
40	0371 02	Blue ●				
30	0371 63	Grey ●	10	1.5 to 16	2.5 to 10	10
30	0371 03	Blue ●				
20	0371 64	Grey ●	16	1.5 to 25	4 to 16	12
20	0371 04	Blue ●				
20	0371 65	Grey ●	35	2.5 to 50	4 to 35	15
20	0371 05	Blue ●				
10	0371 66 ¹	Grey ●	70	25 to 95	16 to 70	22
		1 connection - 2 entries/2 exits				
25	0371 69	Grey ●	4	0.25 to 6	0.25 to 4	6
25	0371 09	Blue ●				
		2 connections on 2 levels				
60	0371 67	Grey ●	2.5	0.25 to 4	0.25 to 2.5	5
60	0371 07	Blue ●				
60	0371 68	Grey ●	4	0.25 to 6	0.25 to 4	6
60	0371 08	Blue ●				
		3 connections on 3 levels				
50	0371 51 ²	Grey ●	2.5	0.25 to 4	0.25 to 2.5	5



Pack	Cat. Nos.	Protection				
		1 connection - 1 entry/1 exit - metal base				
		Screwless fixing on rail up to 10 mm width PEN from 10 mm ²				
		Colour	Nominal cross section (mm ²)	Capacity		Width (mm)
				Rigid cable (mm ²)	Flexible cable (mm ²)	
60	0371 70	Green/yellow ●	2.5	0.25 to 4	0.25 to 2.5	5
50	0371 71	Green/yellow ●				
40	0371 72	Green/yellow ●	6	0.5 to 10	0.25 to 6	8
30	0371 73	Green/yellow ●				
10	0371 74	Green/yellow ●	16	1.5 to 25	4 to 16	12
10	0371 75	Green/yellow ●				
			35	2.5 to 50	4 to 35	15
		1 connection - bare block - metal base				
10	0371 76	-	35	2.5 to 50	4 to 35	15
		1 connection - 2 entries/2 exits - metal base				
		Screwless fixing on rail				
50	0371 79	Green/yellow ●	4	0.25 to 6	0.25 to 4	6
		1 connection - 1 entry/1 exit - plastic base				
		Can be used for protection conductor inside class II equivalent assemblies				
50	0371 77	Green ●	4	0.25 to 6	0.25 to 4	6
40	0371 78	Green ●				
			6	0.5 to 10	0.25 to 6	8
		PNE - Phase/Neutral/Earth				
		3 connections on 3 levels - metal base				
		Green/yellow marking for the lower level Screwless fixing on rail				
		Colour	Nominal cross section (mm ²)	Capacity		Width (mm)
				Rigid cable (mm ²)	Flexible cable (mm ²)	
50	0371 52 ²	Grey ●	2.5	0.25 to 4	0.25 to 2.5	5



CAB 3 marking system **p. 70-73**
 Starfix ferrules and crimping tools **p. 78-79**



1 : Built-in end cap
 2 : Cable capacity - 2.5 mm² max. only when used with bridging comb