

Viking 3 terminal blocks – spring connection

for copper cable



0372 60 + 0372 00 + 0372 20



0372 01




0372 21




0372 63



0372 40

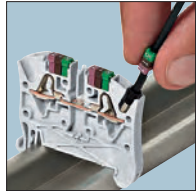

Automatic insertion of stripped cable with ferrule cap or rigid cable up to width of 6 mm

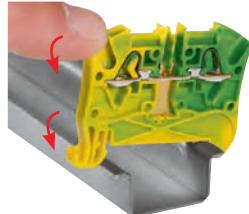

0372 70
Automatic fixing on rail



0372 72



0372 79

Accessories **p. 58-59**
Technical characteristics **p. 62-63**

Screwless connection system, stainless steel spring type
Compatible with either 2 rigid copper cables or flexible cables (0.5 mm² - 16 mm²) with or without ferrules (p. 78)
Direct tool-free insertion of a rigid cable. Direct tool-free insertion of a flexible cable with ferrule, up to 6 mm width
Facility for 2 bridging combs
Compatible with rails EN 60715 depth 7.5 mm and 15 mm

Pack	Cat. Nos.	Connection					
		Grey for standard circuit Blue for neutral conductor Orange for circuit not broken by the master isolating device					
		1 connection - 2 cables - 1 entry/1 exit					
		Colour	Nominal cross section (mm ²)	Rigid cable (mm ²)	Capacity Flexible cable (mm ²)	Flexible cable with ferrule (mm ²)	Width (mm)
60	0372 60	Grey	4	0.5 to 6	0.5 to 4	0.5 to 2.5	5
60	0372 00	Blue					
60	0372 20	Orange					
50	0372 61 ¹	Grey	4	0.5 to 6	0.5 to 4	0.5 to 4	6
50	0372 01 ¹	Blue					
50	0372 21 ¹	Orange					
50	0372 62 ¹	Grey	6	0.5 to 6	0.5 to 6	0.5 to 6	8
50	0372 02 ¹	Blue					
40	0372 63 ¹	Grey	10	0.75 to 10	0.75 to 10	0.75 to 10	10
40	0372 03 ¹	Blue					
10	0372 64 ¹	Grey	16	4 to 16	4 to 16	4 to 16	12
10	0372 04 ¹	Blue					
		1 connection - 3 cables - 1 entry/2 exits					
60	0372 40	Grey	4	0.5 to 6	0.5 to 4	0.5 to 2.5	5
60	0372 41	Blue					
60	0372 42	Orange					
50	0372 43 ¹	Grey	4	0.5 to 6	0.5 to 4	0.5 to 4	6
50	0372 44 ¹	Blue					
		1 connection - 4 cables - 2 entries/2 exits					
60	0372 46	Grey	4	0.5 to 6	0.5 to 4	0.5 to 2.5	5
60	0372 47	Blue					
50	0372 69 ¹	Grey	4	0.5 to 6	0.5 to 4	0.5 to 4	6
50	0372 09 ¹	Blue					
		2 connections - 4 cables - 2 levels					
60	0372 67	Grey	4	0.5 to 6	0.5 to 4	0.5 to 2.5	5
60	0372 07	Blue					
50	0372 68 ¹	Grey	4	0.5 to 6	0.5 to 4	0.5 to 4	6
50	0372 08 ¹	Blue					

1 : Built-in end cap

Pack	Cat. Nos.	Protection					
		Metal base Screwless fixing on rail PEN from 10 mm ²					
		1 connection - 2 cables - 1 entry/1 exit					
		Colour	Nominal cross section (mm ²)	Rigid cable (mm ²)	Capacity Flexible cable (mm ²)	Flexible cable with ferrule (mm ²)	Width (mm)
60	0372 70	Green/yellow	4	0.5 to 6	0.5 to 4	0.5 to 2.5	5
50	0372 71 ¹	Green/yellow	4	0.5 to 6	0.5 to 4	0.5 to 4	6
25	0372 72 ¹	Green/yellow	6	0.5 to 6	0.5 to 6	0.5 to 6	8
20	0372 73 ¹	Green/yellow	10	0.75 to 10	0.75 to 10	0.75 to 10	10
15	0372 74 ¹	Green/yellow	16	4 to 16	4 to 16	4 to 16	12
		1 connection - 3 cables - 1 entry/2 exits					
40	0372 10	Green/yellow	4	0.5 to 6	0.5 to 4	0.5 to 2.5	5
30	0372 11 ¹	Green/yellow	4	0.5 to 6	0.5 to 4	0.5 to 4	6
		1 connection - 4 cables - 2 entries/2 exits					
40	0372 12	Green/yellow	4	0.5 to 6	0.5 to 4	0.5 to 2.5	5
30	0372 79 ¹	Green/yellow	4	0.5 to 6	0.5 to 4	0.5 to 4	6

CAB 3 marking system **p. 70-73**
Starfix ferrules and crimping tools **p. 78-79**

