


Viking 3 terminal blocks – spring connection

for copper cable (continued)

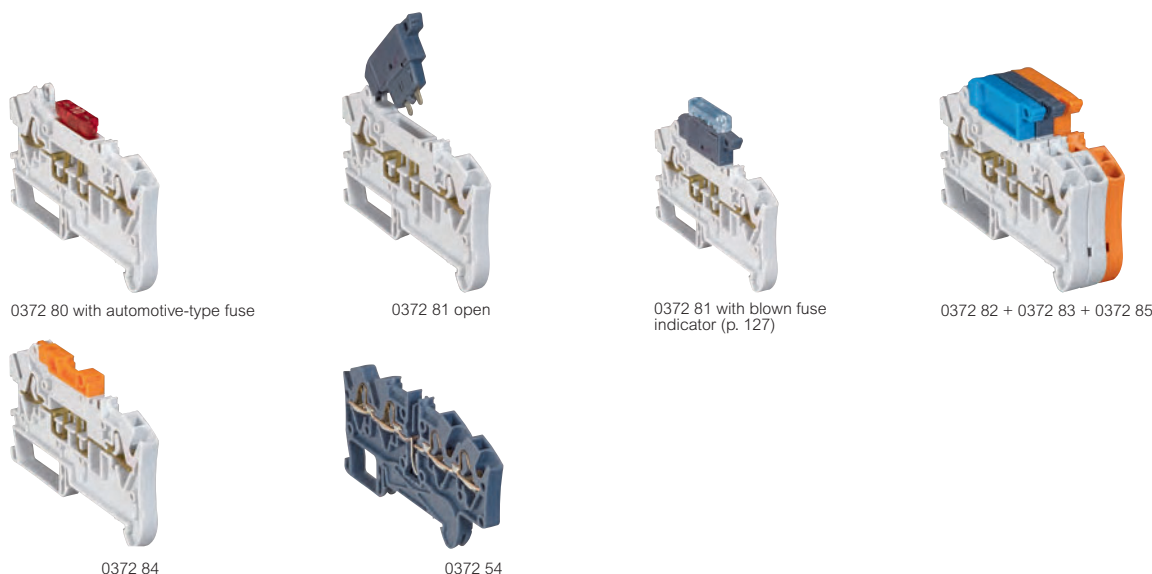

Accessories **p. 58-59**
 Technical characteristics **p. 62-63**

Screwless connection system, stainless steel spring type
 Compatible with either 2 rigid copper cables or flexible cables (0.5 mm² - 16 mm²) with or without ferrules (p. 78)
 Direct tool-free insertion of a rigid cable. Direct tool-free insertion of a flexible cable with ferrule, up to 6 mm width
 Facility for 2 bridging combs
 Compatible with rails EN 60715 depth 7.5 mm and 15 mm

Pack	Cat. Nos.	Disconnection					
		1 connection - 2 cables					
		Disconnection by means of blade type lever, handle lever or mini lever (with tool)					
		Open (to be equipped)					
		Can take a blade-type automotive fuse or a miniature circuit breaker					
			Capacity				
		Colour	Nominal cross section (mm ²)	Rigid cable (mm ²)	Flexible cable (mm ²)	Flexible cable with ferrule (mm ²)	Width (mm)
20	0372 80	Grey ●	2.5	0.5 to 2.5	0.5 to 2.5	0.5 to 2.5	6
		For fuse cartridge 5 x 20 with handle lever					
20	0372 81	Grey ●	2.5	0.5 to 2.5	0.5 to 2.5	0.5 to 2.5	6
		For neutral circuit with blue handle lever					
20	0372 82	Grey/blue ●	2.5	0.5 to 2.5	0.5 to 2.5	0.5 to 2.5	6
		For standard circuit with handle lever					
20	0372 83	Grey ●	2.5	0.5 to 2.5	0.5 to 2.5	0.5 to 2.5	6
		For standard circuit with mini lever					
20	0372 84	Grey ●	2.5	0.5 to 2.5	0.5 to 2.5	0.5 to 2.5	6
		For circuit not broken with handle lever					
		Circuit not broken by the master isolating device					
20	0372 85	Orange ●	2.5	0.5 to 2.5	0.5 to 2.5	0.5 to 2.5	6
		For circuit not broken with mini lever					
		Circuit not broken by the master isolating device					
20	0372 86	Orange ●	2.5	0.5 to 2.5	0.5 to 2.5	0.5 to 2.5	6

Blown fuse indicators p. 59

Pack	Cat. Nos.	Function blocks					
		1 connection - 4 cables - 2 entries/2 outlets - diode-carrier					
			Nominal cross section (mm ²)	Rigid cable (mm ²)	Capacity		Width (mm)
		Colour			Flexible cable (mm ²)	Flexible cable with ferrule (mm ²)	
60	0372 54	Grey ●	4	0.5 to 6	0.5 to 4	0.5 to 2.5	5
		2 connections - 4 cables - 2 levels - diode carrier					
60	0372 55	Grey ●	4	0.5 to 6	0.5 to 4	0.5 to 2.5	5
		2 connections - 4 cables - 2 levels - with LED					
		Voltage presence indicator (12/24V= /~)					
60	0372 56	Grey ●	4	0.5 to 6	0.5 to 4	0.5 to 2.5	5

Accessories p. 58-59

End stops p. 58

CAB 3 marking system **p. 70-73**
 Starfix ferrules and crimping tools **p. 78-79**

