


Viking 3 accessories for terminal blocks

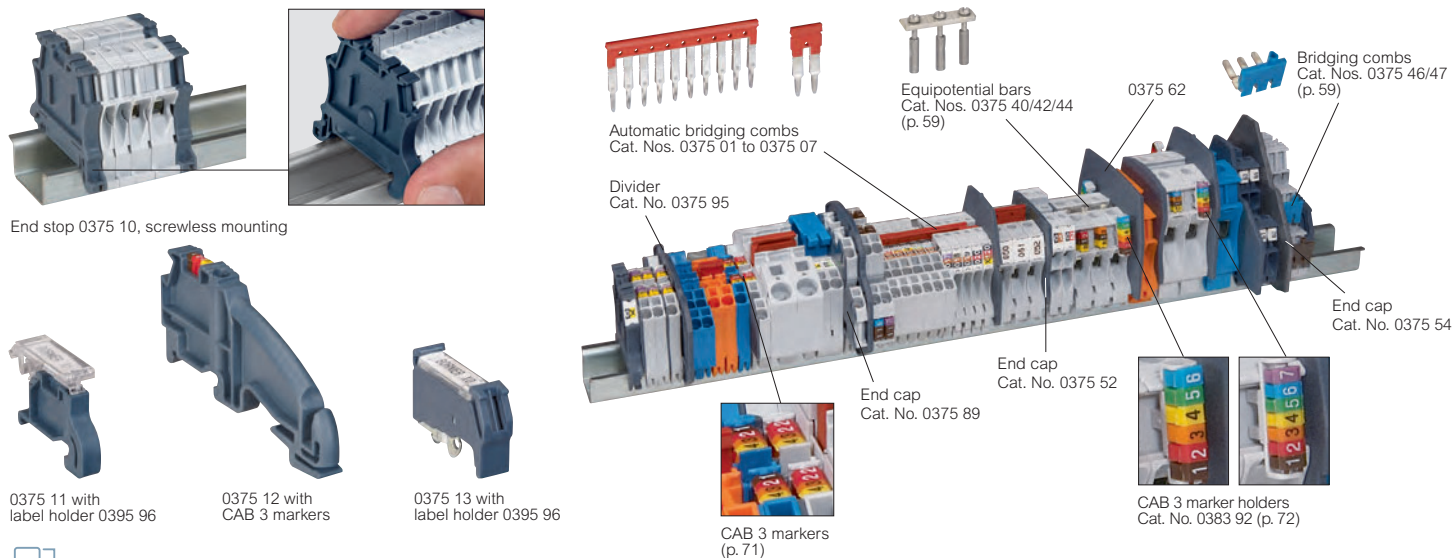

Technical characteristics p. 63

Pack	Cat. Nos.	Rails
10	0374 04	Length 2 m
10	0374 07	EN 60715 depth 7-5 mm
		depth 15 mm
10	0394 49	45° mounting bracket Set of 2 supports for tilting a rail at an angle of 45° Supplied with 4 x M6 screws, nuts and washers
50	0375 10	End stops Grey Compatible with CAB 3 marking system 6 mm width Screwless mounting For rails EN 60715 depth 15 mm and EN 60715 depth 7-5 mm and 15 mm Accepts label holder Cat. No. 0395 96 Acts as end cap for screw terminal blocks 1 entry/1 exit 5, 6, 8 and 10 mm width
20	0375 11	8 mm width For rails EN 60715 depth 15 mm and EN 60715 depth 7-5 mm and 15 mm Accepts label holder Cat. No. 0395 96
10	0375 12	10 mm width For rails EN 60715 depth 15 mm and EN 60715 depth 7-5 mm (except for rail fixed on plate) and 15 mm - IP 2X terminal block with flat steel bar 12 x 2 mm Cat. No. 0048 19 (p. 40) - Copper bar 12 x 4 mm Cat. No. 0373 89 (p. 43) - Shielding bar 10 x 3 mm Cat. No. 0375 34 (p. 59)
20	0375 13	12 mm width For rails EN 60715, EN 60715 depth 15 mm and EN 60715 depth 7-5 mm and 15 mm
20	0395 96	Identification accessories Transparent label holder With variable angle Fixing on end stops Cat. Nos. 0375 10/11 Supplied with label 32 x 9-5 mm Compatible with label Cat. No. 0395 97
20	0395 97	Label For engraving 28 x 9-5 mm For label holder Cat. No. 0395 96. Flexible ABS White background, black engraving
10	0395 98	Black felt tip pen For permanent marking

Pack	Cat. Nos.	End caps
		Grey
		For screw terminal blocks
100	0375 50	1 entry/1 exit 5, 6, 8 and 10 mm width
20	0375 51	1 entry/1 exit 12 and 15 mm width
20	0375 52	2 entries/2 exits
20	0375 53	2 levels
20	0375 54	3 levels
20	0375 55	Disconnection terminal 6 mm width and function blocks 5 mm width
20	0375 56	Disconnection terminal fuse cartridge 5 x 20 with screwed plug
10	0375 57	Disconnection for measurement
		For spring terminal blocks with 5 mm width 5 mm pitch block becomes 6 mm pitch with end cap fitted Permits termination of a 4 mm ² cable complete with ferrule
50	0375 86	1 entry/1 exit
50	0375 87	1 entry/2 exits
20	0375 88	2 entries/2 exits
20	0375 89	2 levels
		For spring terminal blocks with 6 mm width
20	0375 90	Disconnection type
		Separation and insulation dividers
		Grey
		For screw terminal blocks
20	0375 60	1 entry/1 exit 5, 6, 8 and 10 mm width
10	0375 61	1 entry/1 exit 12 and 15 mm width
10	0375 62	2 entry/2 exits and disconnection 6 mm width blocks
10	0375 63	2 levels
		For spring terminal blocks
10	0375 95	1 entry/1 exit, 1 entry/2 exits and 2 entry/2 exits 5 and 6 mm width
10	0375 96	2 levels
		Bridging accessories
		Bridging combs for screw and spring terminal blocks Front mounting (automatic insertion), screwless Isolated and separable. Consecutive or alternating connection. Red
20	0375 01 ¹	For 10 blocks with 5 mm width
50	0375 02 ¹	For 2 blocks with 5 mm width
20	0375 04 ¹	For 10 blocks with 6 mm width
50	0375 05 ¹	For 2 blocks with 6 mm width
20	0375 07 ¹	For 3 blocks with 8 mm width

CAB 3® marking system p. 70-73

1 : Blocks Cat. Nos. 0371 51/52 : upper level only
Block Cat. No. 0372 56 : lower level only