

CAB 3® marking system


for cables and Viking 3 terminal blocks (continued)



Perfect alignment of markers



0382 12

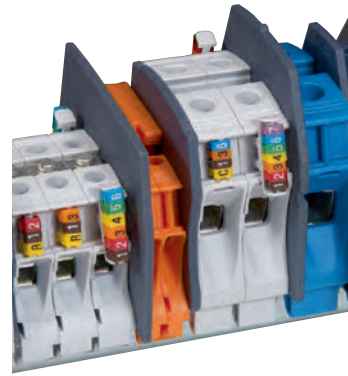

Terminal blocks with CAB 3 markers and label holders

Technical information p. 73

Pack ¹	Cat. Nos.		Markers for cables 0.15 to 0.5 mm ² and 0.5 to 1.5 mm ² cross section and terminal blocks	
	0.15 to 0.5 ²	0.5 to 1.5 ²	On Viking 3 terminal blocks - 4 markers 0.15 to 0.5 mm ² max. - 3 markers 0.15 to 1.5 mm ² max.	
			Digits : international colour code	
1 000	1 200	0381 00	0382 10	0 Black
1 000	1 200	0381 01	0382 11	1 Brown
1 000	1 200	0381 02	0382 12	2 Red
1 000	1 200	0381 03	0382 13	3 Orange
1 000	1 200	0381 04	0382 14	4 Yellow
1 000	1 200	0381 05	0382 15	5 Green
1 000	1 200	0381 06	0382 16	6 Blue
1 000	1 200	0381 07	0382 17	7 Purple
1 000	1 200	0381 08	0382 18	8 Grey
1 000	1 200	0381 09	0382 19	9 White
			Letters : black on yellow background	
300	0381 10	0383 00	A	
300	0381 11	0383 01	B	
300	0381 12	0383 02	C	
300	0381 13	0383 03	D	
300	0381 14	0383 04	E	
300	0381 15	0383 05	F	
300	0381 16	0383 06	G	
300	0381 17	0383 07	H	
300	0381 18	0383 08	I	
300	0381 19	0383 09	J	
300	0381 20	0383 10	K	
300	0381 21	0383 11	L	
300	0381 22	0383 12	M	
300	0381 23	0383 13	N	
300	0381 24	0383 14	O	
300	0381 25	0383 15	P	
300	0381 26	0383 16	Q	
300	0381 27	0383 17	R	
300	0381 28	0383 18	S	
300	0381 29	0383 19	T	
300	0381 30	0383 20	U	
300	0381 31	0383 21	V	
300	0381 32	0383 22	W	
300	0381 33	0383 23	X	
300	0381 34	0383 24	Y	
300	0381 35	0383 25	Z	
			Conventional symbols : black on yellow background	
300	0381 40	0382 70	/	
300	0381 41	0382 71	•	
300	0381 42	0382 72	+	
300	0381 43	0382 73	-	
300	0381 44	0382 74	~	
300		0382 75	≡	
300		0382 76	⊕	

Pack ¹	Cat. Nos.		Markers for cables 1.5 to 2.5 mm ² and 4 to 6 mm ² cross section	
	1.5 to 2.5 ²	4 to 6 ²	Digits : international colour code	
1 200	800	0382 20	0382 30	0 Black
1 200	800	0382 21	0382 31	1 Brown
1 200	800	0382 22	0382 32	2 Red
1 200	800	0382 23	0382 33	3 Orange
1 200	800	0382 24	0382 34	4 Yellow
1 200	800	0382 25	0382 35	5 Green
1 200	800	0382 26	0382 36	6 Blue
1 200	800	0382 27	0382 37	7 Purple
1 200	800	0382 28	0382 38	8 Grey
1 200	800	0382 29	0382 39	9 White
			Letters : black on yellow background	
300	0383 30	0383 60	A	
300	0383 31	0383 61	B	
300	0383 32	0383 62	C	
300	0383 33	0383 63	D	
300	0383 34	0383 64	E	
300	0383 35	0383 65	F	
300	0383 36	0383 66	G	
300	0383 37	0383 67	H	
300	0383 38	0383 68	I	
300	0383 39	0383 69	J	
300	0383 40	0383 70	K	
300	0383 41	0383 71	L	
300	0383 42	0383 72	M	
300	0383 43	0383 73	N	
300	0383 44	0383 74	O	
300	0383 45	0383 75	P	
300	0383 46	0383 76	Q	
300	0383 47	0383 77	R	
300	0383 48	0383 78	S	
300	0383 49	0383 79	T	
300	0383 50	0383 80	U	
300	0383 51	0383 81	V	
300	0383 52	0383 82	W	
300	0383 53	0383 83	X	
300	0383 54	0383 84	Y	
300	0383 55	0383 85	Z	
			Conventional symbols : black on yellow background	
300	0382 80	0382 90	/	
300	0382 81	0382 91	•	
300	0382 82	0382 92	+	
300	0382 83	0382 93	-	
300	0382 84	0382 94	~	
300	0382 85	0382 95	≡	
300	0382 86	0382 96	⊕	

1 : Up to 0.5 mm²: strips of 25 markers
From 0.5 mm² to 2.5 mm²: strips of 30 markers
Upper 2.5 mm²: strips of 20 markers

CAB 3 accessories p. 72
Viking 3 terminal blocks p. 50-67

