



Starfix® ferrules and crimping tools

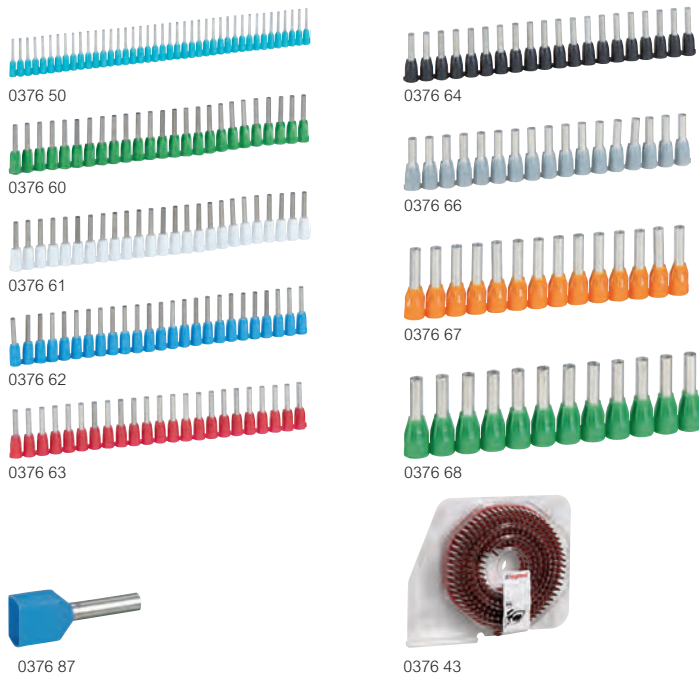

Technical information and dimensions **p. 79**

Pack	Cat. Nos.	Ferrules with insulating flange			
		Provide an equipotential link for all the strands of a flexible conductor Active part in tinned electrolytic copper Conform to NF C 63-023			
		Single ferrules (in strips) Supplied in strips to prevent loss of ferrules			
		For cables cross section (mm ²)	Colour	Strips	Ferrules
500	0376 50	0-25	turquoise	10	50
500	0376 60	0-34	green	10	50
480	0376 61	0-5	white	12	40
480	0376 62	0-75	blue	12	40
1000	0376 63	1-0	red	25	40
1000	0376 64	1-5	black	25	40
1000	0376 66	2-5	grey	25	40
250	0376 67	4-0	orange	10	25
250	0376 68	6-0	green	10	25
		Individual ferrules - single			
100	0376 69	10	brown		
100	0376 70	16	white		
50	0376 71	25	black		
		Individual ferrules - double			
100	0376 87	2 x 0-75	blue		
100	0376 88	2 x 1-0	red		
100	0376 89	2 x 1-5	black		
100	0376 90	2 x 2-5	grey		
		Large capacity refills Large capacity for less frequent applicator reloading Translucent packaging For direct mounting on crimping tool Cat. No. 0376 09			
		Cross section (mm ²)	Colour	Number of ferrules per strip	
3000	0376 41	0-5	White	300	
3000	0376 42	0-75	Blue	300	
3000	0376 43	1-0	Red	300	
3000	0376 44	1-5	Black	300	
2500	0376 45	2-5	Grey	250	

 Colours according to NF C 63-023 standard



Cross sections in mm² :

Pack	Cat. Nos.	Crimping tools for ferrules in strips	
		Cut and carry out 4-point crimping of ferrules from 0-25 to 6 mm ² in one operation Recommended for spring connections Dedicated applicator for each crimping tool for dispensing strips For right and left-handed usage 4 point crimping for Cat. Nos. 0376 08/09 3 point crimping for Cat. No. 0376 10	
1	0376 08	For ferrules with 0-25 and 0-34 mm² cross sections Supplied with empty applicator fitted	
1	0376 09	For ferrules with 0-5 to 2-5 mm² cross sections Fitted with an adjustment wheel Supplied with empty applicator fitted	
1	0376 10	For ferrules with 4 and 6 mm² cross sections Fitted with an adjustment wheel Supplied complete with empty applicator	
1	0376 39	Transport case for on-site use Assorted kit, comprising : - 1 Starfix crimping tool, Cat. No. 0376 09 with empty applicator fitted - 120 x 0-5 mm ² ferrules - 120 x 0-75 mm ² ferrules - 240 x 1-0 mm ² ferrules - 320 x 1-5 mm ² ferrules - 200 x 2-5 mm ² ferrules	
1	0376 97	Multi-purpose crimping tool for 0-5 to 2-5 mm² cross sections Tool cuts, strips, twists, crimps Supplied complete with 5 empty applicators	
1	0376 06	Crimping tool for single and double ferrules Starfix crimping tool for 0-25 to 6 mm² cross sections For 4-point crimping of ferrules from 0-25 to 6 mm ² Recommended for spring connections Crimping tool with disengageable control system, crimping at end For right and left-handed usage	
1	0376 92	Transport case for on-site use Assorted kit. Supplied with : - 1 tool with crimping operation control system for individual ferrules 10 to 50 mm ² - 30 individual ferrules 10 mm ² - 20 individual ferrules 16 mm ² - 15 individual ferrules 25 mm ² - 10 individual ferrules 35 mm ² - 10 individual ferrules 50 mm ²	