

Hypra® Prisinter IP 44/55 - LV 16/32/63 A

selection chart

HYPRAS® PRISINTER IP 44/55 - LV 16/32/63 A

Conform to :
 BS EN 60309-1,
 BS EN 60309-2,
 IP 44 when plug inserted
 IP 54 when used with IP 66/67-55 straight plugs
 IP 55 with cover closed or used with IP 66/67-55 angled plugs
 IK 09 (plastic)
 IK 10 (metal)
 Self-extinguishing : 960 °C
 650 °C for housing
 Temp. rating :
 -20 °C to +100 °C

(Back boxes sold separately)


Technical information and dimensions p. 86-87

			Prisinter				Auxiliary c/o contact microswitch
			Panel mounting sockets		Surface mounting sockets		
LV			METAL	PLASTIC	METAL	PLASTIC	
100 to 130 V 50/60 Hz	16 A	2 P + ⊥	-	0519 10	0520 59	0519 10+ 0520 49	0521 96
		3 P + N + ⊥	-	0520 02	-	0520 02+ 0520 49	0521 96
200 to 250 V 50/60 Hz	16 A	3 P + ⊥	-	0520 03	-	0520 03+ 0520 49	0521 96
		3 P + N + ⊥	-	0520 04	-	0520 04+ 0522 49	0521 96
		32 A	2 P + ⊥	-	0527 02	-	0527 02+ 0529 49
380 to 415 V 50/60 Hz	16 A	3 P + ⊥	0522 13	0522 03	0522 13+ 0520 59	0522 03+ 0520 49	0521 96
		3 P + N + ⊥	0522 14	0522 04	0522 14+ 0529 59	0522 04+ 0522 49	0521 96
	32 A	3 P + ⊥	0529 13	0529 03	0529 13+ 0522 59	0529 03+ 0529 49	0521 96
		3 P + N + ⊥	0529 14	0529 04	0529 14+ 0522 59	0529 04+ 0529 49	0521 96
	63 A	3 P + ⊥	0538 00	0536 03	0538 00+ 0538 09	0536 03+ 0537 49	0521 96
3 P + N + ⊥		0538 01	0536 04	0538 01+ 0538 09	0536 04+ 0537 49	0521 96	

For pack quantities, see opposite and p. 85

Hypra® Prisinter IP 44/55 - LV 16 A

interlocked switched sockets

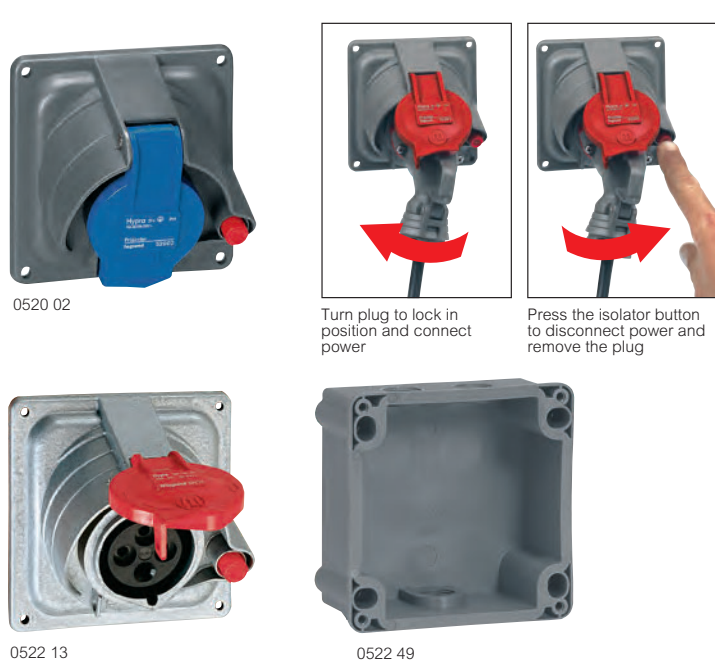

Technical information and dimensions p. 86-87
 Conformity to International Standards p. 128

Conform to BS EN 60309-1, BS EN 60309-2
 IP 44 when plug inserted
 IP 54 when used with IP 66/67-55 straight plugs
 IP 55 with cover closed or used with IP 66/67-55 angled plugs
 IK 09 (plastic)
 IK 10 (metal)
 Stainless steel screws
 Brass contacts

Pack	Cat. Nos.			
1	Metal	Plastic	100/130 V ~	
			0519 10	2 P + ⊥
			200/250 V ~	
1	Metal	Plastic	0520 02	2 P + ⊥
1			0520 03	3 P + ⊥
1			0520 04	3 P + N + ⊥
1	Metal	Plastic	380/415 V ~	
			0522 13	3 P + ⊥
1	0522 14	0522 04	3 P + N + ⊥	

		Surface mounting boxes			
1	Metal	Plastic	0520 59	0520 49	For 2 P + ⊥ / 3 P + ⊥ sockets

IP 44 straight plugs p. 90-92



IP 66/67-55 angled and straight plugs p. 97-98

