

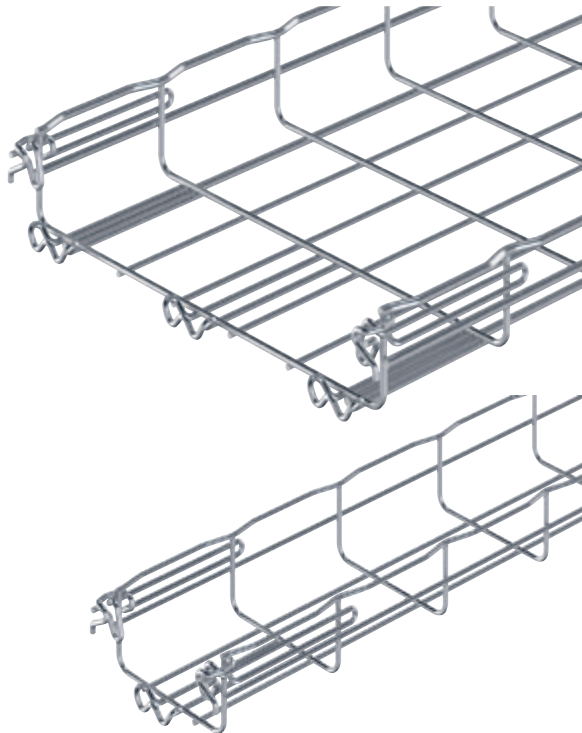
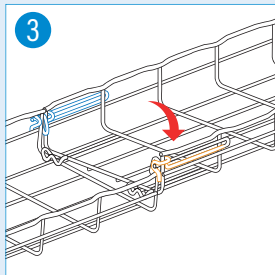


→ FC54 - FASCLIC AUTO+ **N**

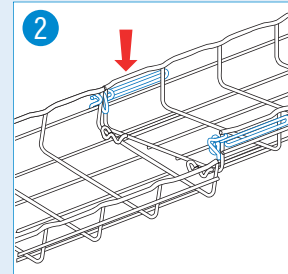

MONTAGE

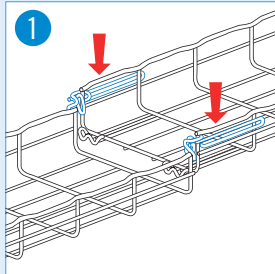

ÉLÉMENTS TECHNIQUES

Courbes de charges / portée

54 mm  
 3 m  
 R<1m  
 50->600 mm

	L (mm)	Emb.	EZ	HR	304L	316L
FC 54/50	50	3 M	200 061	200 066	200 068	200 064
FC 54/100	100	3 M	200 071	200 076	200 078	200 074
FC 54/150	150	3 M	200 081	200 086	200 088	200 084
FC 54/200	200	3 M	200 091	200 096	200 098	200 094
FC 54/300	300	3 M	200 101	200 106	200 108	200 104
FC 54/400	400	3 M	200 201	200 206	200 208	200 204
FC 54/450	450	3 M	200 251	200 256	200 258	200 254
FC 54/500	500	3 M	200 301	200 306	200 308	200 304
FC 54/600	600	3 M	200 401	200 406	200 408	200 404

