




CHEMINS DE CÂBLES FILS CABLOFIL

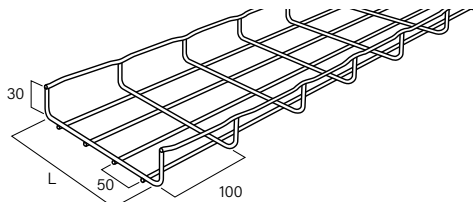

→ CF 30 STANDARD



30 mm



50 -> 600 mm



3 m

L
(mm)

Emb.

EZ

HR

GC


304L

316L

CF 30/50 (bord droit)	50	3 M	000 011*	000 016*	000 013*	000 018*	000 014*
CF 30/100	100	3 M	000 021	000 026	000 023	000 028	000 024
CF 30/150	150	3 M	000 031	000 036	000 033	000 038	000 034
CF 30/200	200	3 M	000 041	000 046	000 043	000 048	000 044
CF 30/300	300	3 M	000 051	000 056	000 053	000 058	000 054
CF 30/400	400	3 M	000 801	000 806	000 803	000 808	000 804
CF 30/500	500	3 M	000 811	000 816	000 813	000 818	000 814
CF 30/600	600	3 M	000 851	000 856	000 853	000 858	000 854

ÉLÉMENTS TECHNIQUES

Courbes de charges / portée

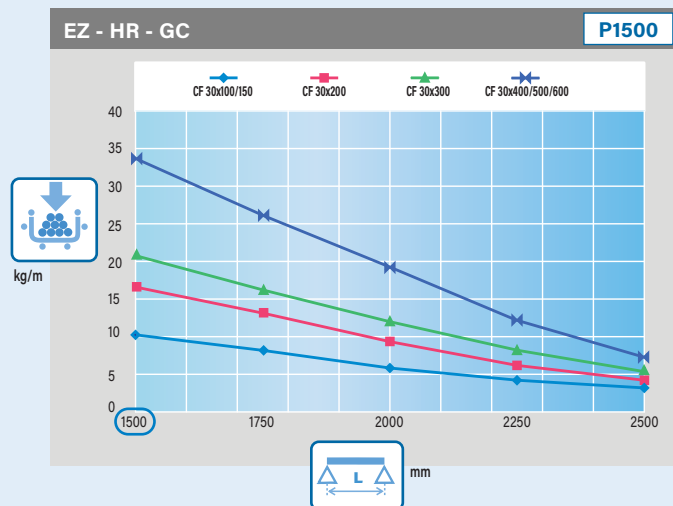

Contenance en kg/m : poids indicatif des câbles lors d'un remplissage à 100% du chemin de câbles

Références	Contenance maximum (Kg/m)	
	d = 0,15 (VDI)	d = 0,25 (puissance)
CF 30/50	2,1	3,5
CF 30/100	4,2	7,0
CF 30/150	6,3	10,5
CF 30/200	8,4	14,0
CF 30/300	12,6	21,0
CF 30/400	16,8	28,0
CF 30/500	21,0	35,0
CF 30/600	25,2	42,0

* Chemin de câbles fil avec bord droit



Éclissage
p. 116-119