

ÉCLISSAGE TRADITIONNEL

→ ÉCLISSES CE



CF 30 à CF 105 - HDF 105
50 -> 600 mm

Emb.

GS

EZ

HR

304L

316L

CE25	Sac 50 P	558 011	-	350 569	558 018	558 014
CE30	Sac 50 P	558 041	-	350 570	558 048	558 044
BTRCC 6 X 20	Sac 100 P	-	801 011	350 402	801 018	801 014
CE25VS	Sac 50 P	558 021	-	350 571	-	-
CE30ES	Sac 50 P	558 031	-	350 572	-	-
EEC6	Sac 100 P	801 201	-	-	-	801 204
EAC	Sac 20 P	-	558 403	-	-	-
KITFIL UNIFIX	Sac 10 P	-	350 503	-	-	-

Emb.


GS

HR

316L

KITFIXTR (CE25 + BTRCC 6 X 20)	Sac 50 P	558 091	350 426	-
KITASSTR (CE30 + CE25 + BTRCC 6 X 20)	Sac 50 P	558 081	350 424	-
KITFIXVS (CE25VS + EEC6)	Sac 50 P	558 061	350 428	-
KITASSVS (CE25ES + CE30VS)	Sac 50 P	558 071	350 427	-
KITINOX (CE25VS + CE30 + EEC6)	Sac 50 P	-	-	558 954

INFORMATIONS

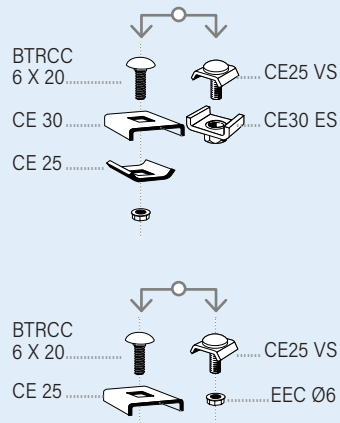

Les kits

