


# COUVERCLES ET CORNIÈRES

## → COUVERCLES CP - CVN (UNIQUEMENT COMPATIBLES CHEMINS DE CÂBLES CABLOFIL)

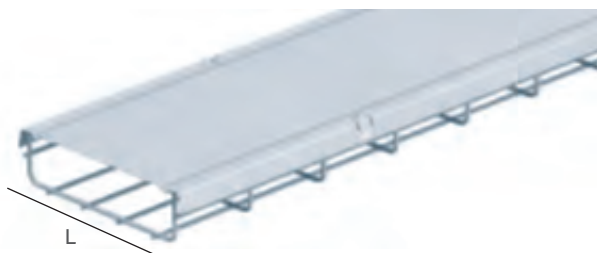

50 -> 600 mm

CF 30 - CF 54 - CF 105  
50 -> 600 mm

1 ou 2 m

Montage sur CF30 par clips F01 ou pattes rabattables  
Montage sur CF54 et 105 par clips F02 ou pattes rabattables

	L (mm)	Emb.	GS	GC	HR	316L
<b>CP 50</b>	71	2 M	646 010	646 013	350 664	646 014
<b>CP 100</b>	121	2 M	646 020	646 023	350 665	646 024
<b>CP 150</b>	171	2 M	646 030	646 033	350 666	646 034
<b>CP 200</b>	221	2 M	646 040	646 043	350 667	646 044
<b>CP 300</b>	322	2 M	646 050	646 053	350 668	646 054
<b>CP 400</b>	425	2 M	646 060	646 063	350 669	646 064
<b>CP 500</b>	525	2 M	646 070	646 073	350 671	646 074
<b>CP 600</b>	625	2 M	646 080	646 083	350 672	646 084

	L (mm)	Emb.	GS	GC	HR	316L
<b>CVN 50*</b>	71	3 M	629 050	629 053	629 056	629 054
<b>CVN 100*</b>	121	3 M	629 100	629 103	629 106	629 104
<b>CVN 150*</b>	171	3 M	629 150	629 153	629 156	629 154
<b>CVN 200*</b>	221	3 M	629 200	629 203	629 206	629 204
<b>CVN 300*</b>	322	3 M	629 300	629 303	629 306	629 304
<b>CVN 400*</b>	425	3 M	629 400	629 403	629 406	629 404
<b>CVN 450*</b>	475	3 M	629 450	629 453	629 456	-
<b>CVN 500*</b>	525	3 M	629 500	629 503	629 506	629 504
<b>CVN 600*</b>	625	3 M	629 600	629 603	629 606	629 604

\* Livré en 3 longueurs de 1 m

### MONTAGE

#### Avec clips F01/F02

Clips imperdables



Clip F01



Clip F02



#### Avec pattes rabattables

