

 
# CHEMINS DE CÂBLES PVC

## GAMME ISI PLAST™ - COMPOSANTS

### → SÉPARATEUR



637 788



RAL 7030

Emb.

Hauteur 50 mm	42 M	637 788
Hauteur 75 mm	30 M	637 888
Hauteur 100 mm	24 M	637 988

### → ÉCLISSES



637 793


RAL 7030

Emb.


Variable légère*	20 P	637 793
Bande plate	10 M	019 159

\*2 par longueur

### → DALLES MARINE

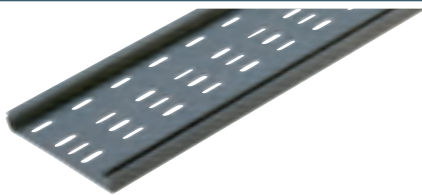

637 995

 

RAL 7030

Emb.  **HR**

50 x 50 mm	3 M	-	485 330
75 x 17 mm	24 M	637 995	-
150 x 17 mm	18 M	637 997	-

### → CONSOLES MÉTAL ÉPOXY




637 978

RAL 7030

Emb.

Largeur 300 mm	2 P	637 978
Largeur 400 mm	2 P	637 979
Largeur 500 mm	2 P	637 980
Largeur 600 mm	2 P	637 981

### → RAILS

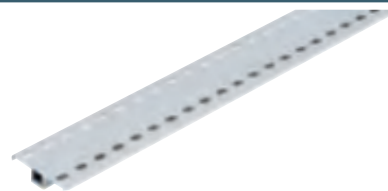

637 956



RAL 7030

Emb. Réf.

Rail Téléx PVC 50 x 17	20 M	637 994
Télé rail PVC 80 x 19,6	42 M	637 956

### → VISSERIE ET SOUDURE PVC



637 954

RAL 7030

Emb. Réf. **304L** **316L**

Boulon polyamide M8x20	100 P	637 953	-	-
Pion fixation rapide	100 P	637 954	-	-
Visserie inox BTRCC6X20	100 P	-	801 018	801 014
Visserie inox BTRCC8X20	50 P	-	-	801 034
Goupille PVC	100 P	637 951	-	-
Goupille inox	50 P	-	637 952	-