
 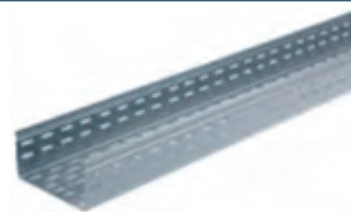


CHEMINS DE CÂBLES TÔLE PERFORÉE ET NON PERFORÉE

P31 HD - GAMME P31 HD

→ P31 HD HAUTEUR 100



	L (mm)	Ep (mm)	Emb.	GS	GC
P31 HD 100/100	100	1.5	3 M	487 409	487 425
P31 HD 100/100 ⁽¹⁾	100	1.5	3 M	487 320	487 323
P31 HD 100/150	150	1.5	3 M	487 410	487 426
P31 HD 100/150 ⁽¹⁾	150	1.5	3 M	487 330	487 333
P31 HD 100/200	200	1.5	3 M	487 411	487 427
P31 HD 100/200 ⁽¹⁾	200	1.5	3 M	487 340	487 343
P31 HD 100/300	300	1.5	3 M	487 412	487 428
P31 HD 100/300 ⁽¹⁾	300	1.5	3 M	487 360	487 363
P31 HD 100/400	400	1.5	3 M	487 413	487 429
P31 HD 100/400 ⁽¹⁾	400	1.5	3 M	487 370	487 373
P31 HD 100/500	500	1.5	3 M	487 414	487 430
P31 HD 100/500 ⁽¹⁾	500	1.5	3 M	487 380	487 383
P31 HD 100/600	600	1.5	3 M	487 415	487 431
P31 HD 100/600 ⁽¹⁾	600	1.5	3 M	487 390	487 393
	L (mm)	Ep (mm)	Emb.	GS	GC
P31 HD 100/100	100	2	3 M	487 441	487 458
P31 HD 100/150	150	2	3 M	487 442	487 459
P31 HD 100/200	200	2	3 M	487 443	487 460
P31 HD 100/300	300	2	3 M	487 445	487 461
P31 HD 100/400	400	2	3 M	487 446	487 462
P31 HD 100/500	500	2	3 M	487 447	487 463
P31 HD 100/600	600	2	3 M	487 448	487 464

(1) Non perforé