


# FIXATION MURALE

## CHARGES LÉGÈRES À MOYENNES

### → CONSOLES CSN

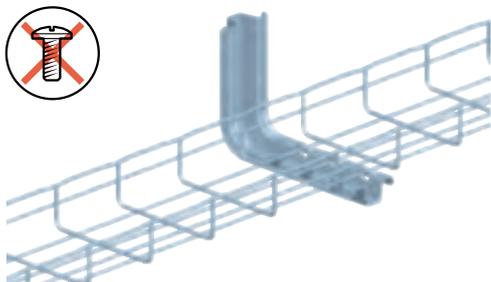

556 100



↔ 100 -> 500 mm



**FASLOT**  
FAST ASSEMBLING SYSTEM



Peut également être fixé :

- sur rail
- sur pendard

Montage sur rail R21/41 avec accessoire INTERFAS (p. 214)


	Charge (daN)	L (mm)	Emb.	GS	GC	Emb.	304L	316L
<b>CSN 100</b>	130	178	5 P	<b>556 100</b>	556 103	20 P	556 108	556 104
<b>CSN 150</b>	110	228	5 P	<b>556 110</b>	556 113	20 P	556 118	556 114
<b>CSN 200</b>	85	278	5 P	<b>556 120</b>	<b>556 123</b>	20 P	556 128	556 124
<b>CSN 300</b>	73	378	20 P	<b>556 130</b>	556 133	20 P	556 138	556 134
<b>CSN 400</b>	56	478	10 P	<b>556 140</b>	556 143	-	-	-
<b>CSN 450</b>	50	528	8 P	556 150	556 153	-	-	-

### MONTAGE ET DIMENSIONS

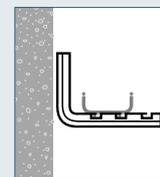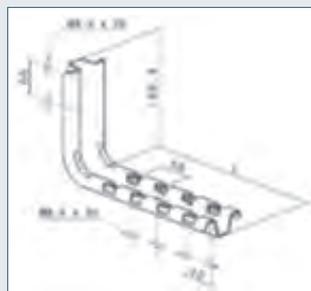

Épaisseur renforcée pour largeur 300

### FIXATION DU CHEMIN DE CÂBLES

 


### → CONSOLES CSNC



↔ 100 -> 500 mm



**FASLOT**  
FAST ASSEMBLING SYSTEM

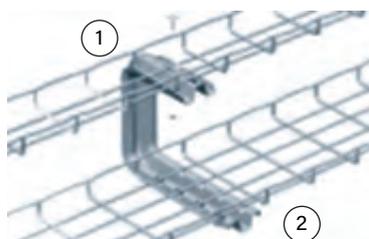



556 300

Peut également être fixé :

- sur rail
- sur pendard



	Charge (daN)	L1 (mm)	L2 (mm)	Emb.	GS	GC	316L
<b>CSNC100</b>	120	170	178	10 P	<b>556 300</b>	556 303	556 304
<b>CSNC150</b>	100	170	228	10 P	<b>556 310</b>	556 313	556 314
<b>CSNC200</b>	80	170	278	10 P	<b>556 320</b>	556 323	556 324
<b>CSNC300</b>	70	288	378	10 P	<b>556 330</b>	556 333	556 334
<b>CSNC400</b>	48	288	478	4 P	556 340	556 343	-
<b>CSNC450</b>	44	288	528	4 P	556 350	556 353	-

### MONTAGE ET DIMENSIONS

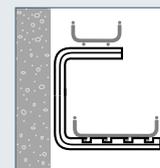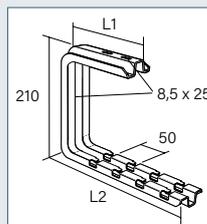

Épaisseur renforcée pour largeur 300

### FIXATION DU CHEMIN DE CÂBLES

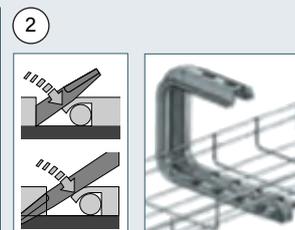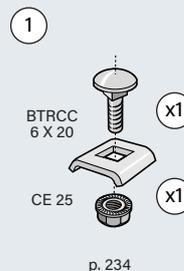

Recourber la patte d'accrochage sur le fil

Vis : - 1 point de fixation jusqu'à la largeur 200 mm incluse  
- 2 points de fixation à partir de la largeur 300 mm