

FIXATION MURALE

CHARGES LÉGÈRES À MOYENNES

→ CONSOLES CLN



556 200

CF 30 à CF 150
 100 -> 300 mm


25 -> 100 mm
 100 -> 300 mm



Peut également être fixé :
- sur pendard

	Charge (daN)	L (mm)	Emb.	GS	GC
CLN100	95	150	5 P	556 200	556 203
CLN150	70	200	5 P	556 210	556 213
CLN200	40	250	20 P	556 220	556 223
CLN300	25	350	20 p	556 230	556 233

MONTAGE ET DIMENSIONS

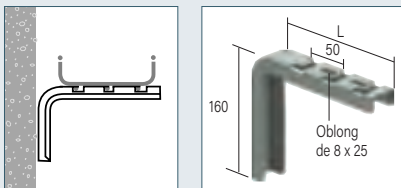

FIXATION DU CHEMIN DE CÂBLES



Vis : - 1 point de fixation jusqu'à la largeur 200 mm incluse
 - 2 points de fixation à partir de la largeur 300 mm

→ CONSOLES CL



522 140


CF 30 à CF 150
 150 -> 400 mm

25 -> 100 mm
 100 -> 300 mm

Peut également être fixé :
- sur pendard

	Charge (daN)	L (mm)	H (mm)	Emb.	GS	GC
CL 150	65	167	83	5 P	522 140	522 141
CL 200	42	247	83	5 P	557 280	557 283
CL 250	42	243	203	5 P	522 142	522 143
CL 300	35	327	123	5 P	557 290	557 293
CL 350	30	363	283	5 P	522 144	522 145

DIMENSIONS

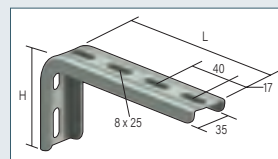

FIXATION DU CHEMIN DE CÂBLES

