


# FIXATION MURALE

## CHARGES LÉGÈRES À MOYENNES

### → CONSOLES CS

 CF 30 à CF 150  
 ↳ 100 -> 300 mm  
 ↳ 50 -> 300 mm

 ↳ 25 -> 100 mm  
 ↳ 100 -> 300 mm




 
002 700

Peut également être fixé :  
 - sur pendard



Charge (daN)    L (mm)    Emb.    **GS**    **GC**    Emb.    **316L**

<b>CS 100</b>	72	170	5 P	<b>002 700</b>	<b>002 703</b>	40 p	002 704
<b>CS 200</b>	67	245	5 P	<b>002 710</b>	<b>002 713</b>	20 p	002 714
<b>CS 300</b>	70	345	5 P	<b>002 720</b>	<b>002 723</b>	20 p	002 724

### MONTAGE ET DIMENSIONS

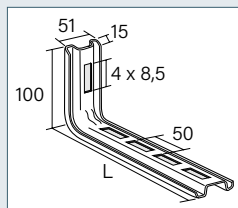

### FIXATION DU CHEMIN DE CÂBLES

  


Vis : - 1 point de fixation jusqu'à la largeur 200 mm incluse  
 - 2 points de fixation à partir de la largeur 300 mm

### → CONSOLES CSCC - CSC

 CF 30 à CF 100  
 ↳ 100 -> 300 mm

 ↳ 25 -> 100 mm  
 ↳ 100 -> 300 mm

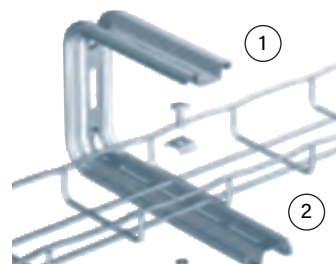

002 760


Peut également être fixé :  
 - sur pendard

Au-delà de 300 mm de largeur, utiliser la CCP21S (p. 210)

Charge (daN)    L1 (mm)    L2 (mm)    Emb.    **GS**    **GC**    **316L**


<b>CSC 100</b>	73	130	168	20 P	<b>002 760</b>	002 763	002 764
<b>CSC 200</b>	60	180	260	10 P	<b>002 770</b>	002 773	002 774
<b>CSC 300</b>	48	230	360	10 P	<b>002 780</b>	002 783	002 784
<b>CSCC 100</b>	73	130	168	10 P	<b>012 760</b>	012 763	012 764
<b>CSCC 200</b>	60	180	260	10 P	<b>012 770</b>	012 773	012 774
<b>CSCC 300</b>	48	230	360	10 P	<b>012 780</b>	012 783	012 784

### MONTAGE

 


### DIMENSIONS

#### CSC

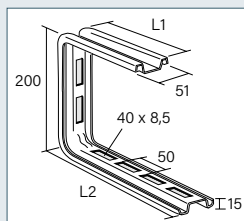

#### CSCC

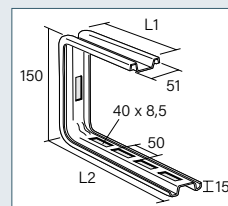

### FIXATION DU CHEMIN DE CÂBLES

