



FIXATION PLAFOND SUSPENSION CENTRALE

→ SUSPENTES CENTRALES SCF



586 200



Pour suspension centrale par tige filetée (Ø 8 à 12 mm) + écrous et contre-écrous à embase, livrée avec un tube pour le passage de la tige filetée



Peut également être fixé :
- sur tige filetée

	Charge (daN)	L (mm)	Emb.	GS	HR
SCF150	300	144	10 P	-	586 156
SCF200	340	194	10 P	586 200	586 206
SCF300	160	294	10 P	586 300	586 306
SCF400	140	394	10 P	586 400	586 406
SCF500	120	494	10 P	586 500	586 456
SCF600	100	594	15 P	586 600	586 506
PFSCF - Platine	-	100	50 P	586 210	586 606



	H1 (mm)	Emb.	GS
EXT-SCF50	50	50 P	586 810
EXT-SCF100	100	100 P	586 820
EXT-SCF150	150	50 P	586 830
EXT-SCF325	325	50 P	586 840

MONTAGE ET DIMENSIONS



SCF

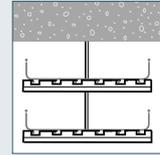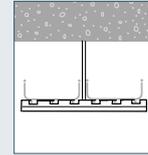

PFSCF

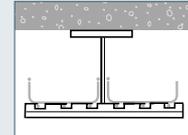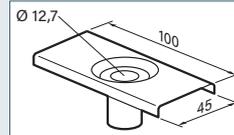


EXT-SCF

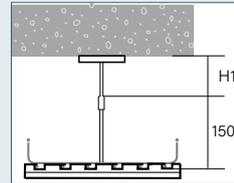 



FIXATION DU CHEMIN DE CÂBLES



FIXATION SUR TIGE FILETÉE

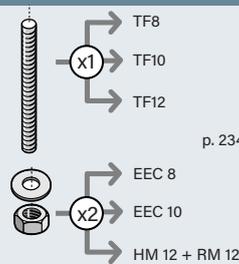

→ CEQ

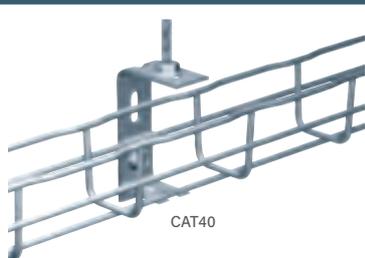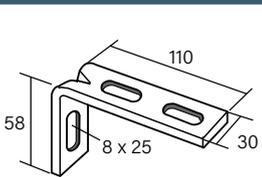


557 300



À associer à CAT40 pour suspente

	Charge (daN)	Emb.	GS	GC	316L
CEQ	12	25 P	557 300	557 303	557 304

→ STF PU

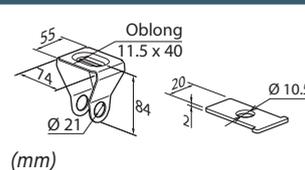

(mm)

Emb. **GS**

STF PU : support tige filetée - plafond universel 10 P 150 (0° -> 45°) 100 (45° -> 90°) **350 578**