



FIXATION PLAFOND EN BALANCE

→ CONSOLES CSNC



556 300





100 -> 500 mm



Peut également être fixé :
- sur rail
- sur pendentif


	Charge (daN)	L1 (mm)	L2 (mm)	Emb.	GS	GC	316L
CSNC100	120	170	178	10 P	556 300	556 303	556 304
CSNC150	100	170	228	10 P	556 310	556 313	556 314
CSNC200	80	170	278	10 P	556 320	556 323	556 324
CSNC300	70	288	378	10 P	556 330	556 333	556 334
CSNC400	48	288	478	4 P	556 340	556 343	-
CSNC450	44	288	528	4 P	556 350	556 353	-

MONTAGE ET DIMENSIONS

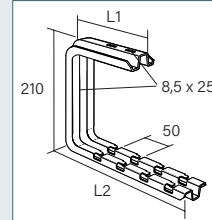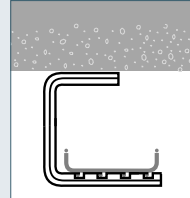


Épaisseur renforcée pour largeur 300

 FIXATION DU CHEMIN DE CÂBLES



Recourber la patte d'accrochage sur le fil

→ ATTACHES DE SUSPENSION AS

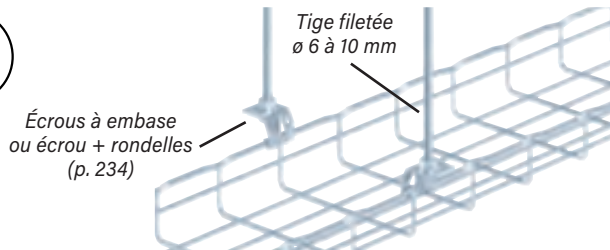

350 581

Écrous à embase ou écrou + rondelles (p. 234)

Tige filetée ø 6 à 10 mm




CF 30 à CF 150
ZF31 H 25 à 100
100 -> 600 mm




100 -> 600 mm

	Charge (daN)	Emb.	GS	HR	316L
AS	100	50 P	350 581	350 587	350 583


MONTAGE

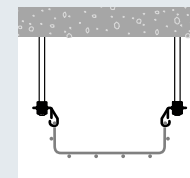


DIMENSIONS

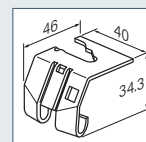

FIXATION DU CHEMIN DE CÂBLES

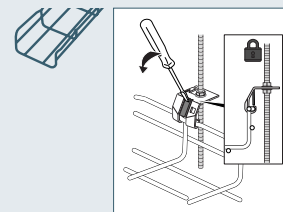

FIXATION SUR TIGE FILETÉE

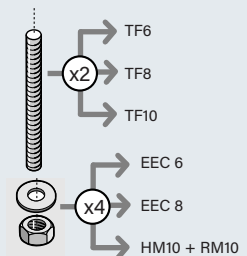

p. 234



Rails R21/R41
 p. 208