




FIXATION PLAFOND

PENDARDS MOYENS


→ EDF

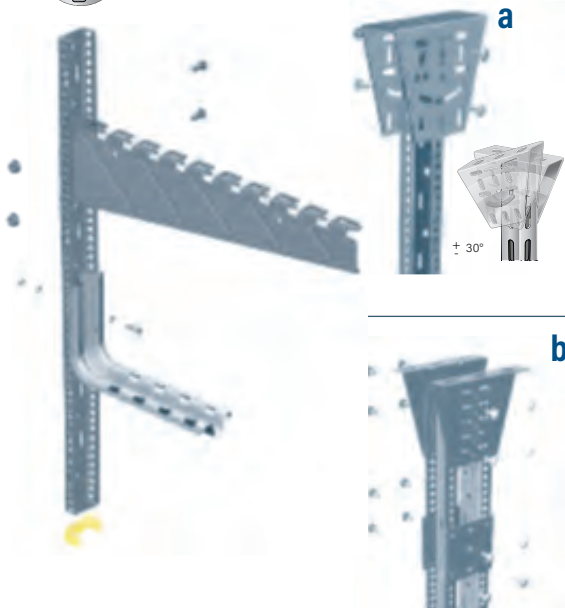


	L mm	H mm	daN.m	Emb.	GS	GC	Emb.	304L	316L
EDF 2000	1980	-	-	2 M	561 010	561 013	2 M	561 018	561 014
				Emb.	PVC				
EPEDF	-	-	-	50 P	559 615	-	-	-	-
				Emb.	GS	GC	Emb.		316L
PFREDF	-	-	18	10 P	561 080	-	10 P	-	561 084
DF	-	-	28	20 P	561 060	561 063	4 P	-	561 064
DFA	-	-	-	20 P	561 040	561 043	-	-	-
SPST	-	-	-	10 P	561 300	561 303	-	-	-
				Emb.	GS	GC	Emb.	HR	316L
ERD10	-	-	-	10 P	561 050	561 053	-	-	-
CLMU	-	-	18	10 P	559 090	-	10 P	559 097	559 094
				Fixation latérale	Emb.	GS	Emb.	HR	316L
CB50	50	69	50	10 P	350 800	-	10 P	-	350 804
CB100	100	69	50	10 P	350 810	-	10 P	350 816	350 814
CB150	150	72,4	40	10 P	350 820	-	10 P	350 826	350 824
CB200	200	72,4	40	10 P	350 830	-	10 P	350 846	350 834
CB300	300	85,4	60	10 P	350 840	-	10 P	350 856	350 844
CB400	400	99	120	10 P	350 850	-	10 P	350 866	350 854
CB500	500	136,9	110	10 P	350 860	-	10 P	350 876	350 864
CB600	600	136,9	-	10 P	350 870	-	10 P	350 806	350 874



MONTAGE

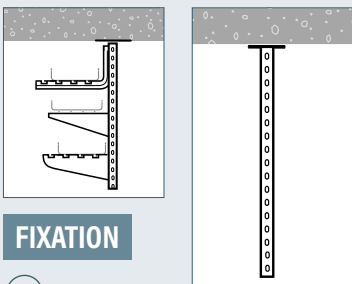


FIXATION

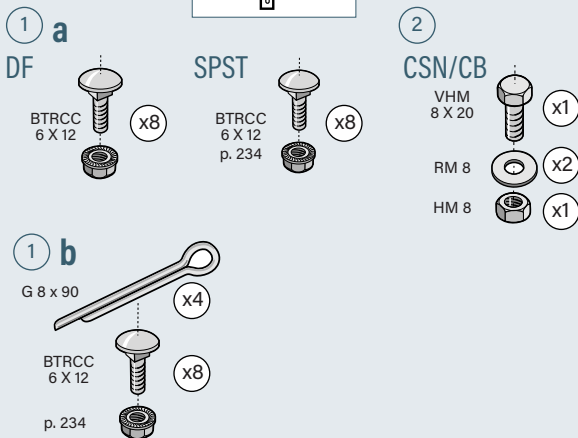


DIMENSIONS


PFREDF

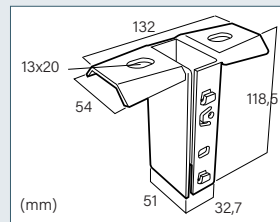


DF

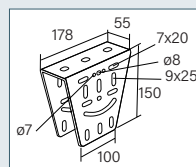


SPST

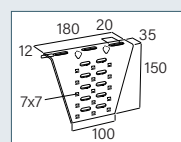


DFA

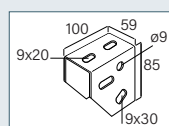


EDF

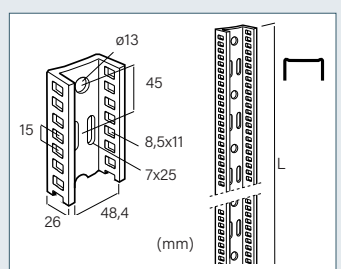


CLMU

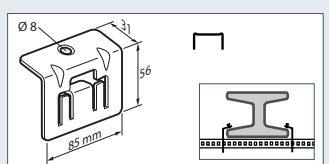

ERD10

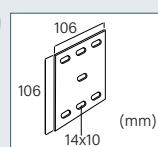

CB

 

EPEDF



Vis : - 1 point de fixation jusqu'à la largeur 200 mm incluse
 - 2 points de fixation à partir de la largeur 300 mm

++ Consoles CSN
 p. 192