


FIXATION PLAFOND

PENDARDS MOYENS GAMME 41


→ R21S

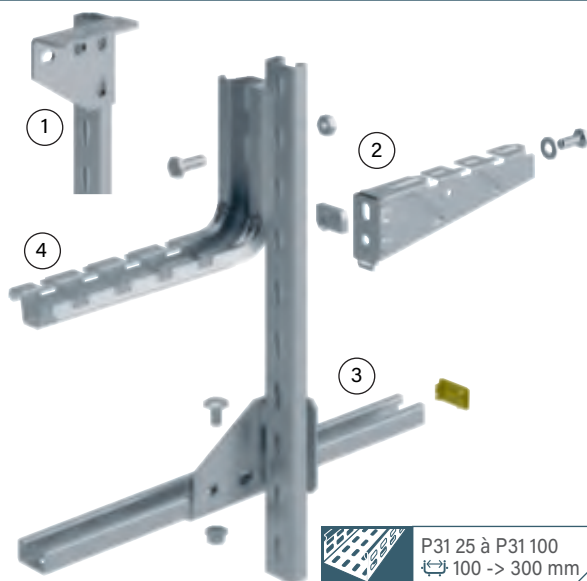

P31 25 à P31 100
↔ 100 -> 300 mm

CF 30 à CF 105
↔ 100 -> 300 mm

MONTAGE

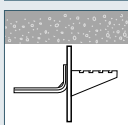


FIXATION DU CHEMIN DE CÂBLE

FASTRUT
FAST ASSEMBLY SYSTEM



p. 200 et 220

FIXATION

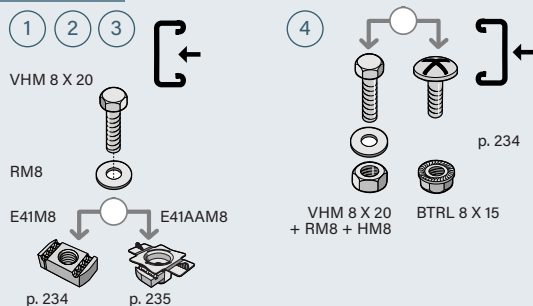


p. 234



p. 234

p. 235


DIMENSIONS

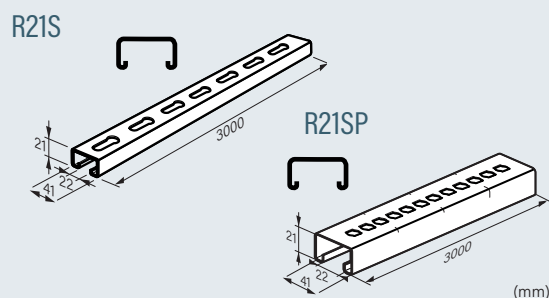



DIMENSIONS (SUITE)

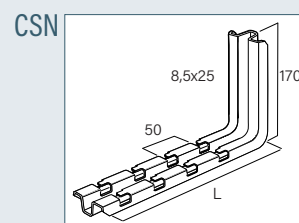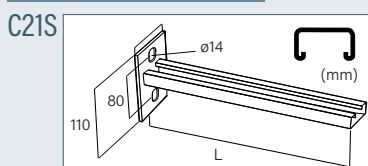

INTERFAS

 

CC21S/PC21S

 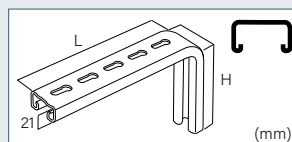

	L mm	Δ mm	⊙ daN.m	Emb.	GS	GC	HR	Emb.	304L	316L
R21S3000 E15	3000	1,5	-	3 M	342 180	342 183	-	-	-	342 184
R21S3000 E20	3000	2	-	3 M	343 230	343 233 343 236	-	343 238	343 234	
R21S3000 E25	3000	2,5	-	3 M	343 240	343 243	-	-	343 244	
R21SP3000 E20	3000	2	-	3 M	348 049	-	-	-	-	
SU41	-	-	35	10 P	595 340	-	-	-	-	
				Emb.	PVC					
EP21	-	-	-	50 P	348 576	-	-	-	-	
		H mm	F daN	Emb.	GS	GC				316L
C21S 150	150	-	250	24 P	-	597 013	-	-	-	
C21S 200	200	-	180	24 P	-	597 023	-	-	-	
C21S 300	300	-	130	20 P	-	597 033	-	-	-	
CC21S 150	150	100	135	10 P	557 860	-	-	-	-	557 864
CC21S 200	200	150	108	10 P	557 870	-	-	-	-	557 874
CC21S 300	300	200	80	10 P	557 880	-	-	-	-	557 884
				Emb.	GS					316L
PC21S 500	500	-	24	10 P	557 900	-	-	-	-	557 904
PC21S 800	800	-	24	5 P	557 910	-	-	-	-	557 914
				Emb.	GS	GC		Emb.	304L	316L
CSN 100	178	-	130	5 P	556 100	556 103	-	20 P	556 108	556 104
CSN 150	228	-	110	5 P	556 110	556 113	-	20 P	556 118	556 114
CSN 200	278	-	85	5 P	556 120	556 123	-	20 P	556 128	556 124
CSN 300	378	-	73	20 P	556 130	556 133	-	20 P	556 138	556 134
				Emb.	GS	ZnL				
INTERFAS	100	-	-	10 P	557 800	557 803	-	-	-	-
				Emb.	GS				HR	316L
CB50	50	69	80	10 P	350 800	-	-	-	-	350 804
CB100	100	69	110	10 P	350 810	-	-	-	350 816	350 814
CB150	150	72,4	100	10 P	350 820	-	-	-	350 826	350 824
CB200	200	72,4	110	10 P	350 830	-	-	-	350 846	350 834
CB300	300	85,4	150	10 P	350 840	-	-	-	350 856	350 844