


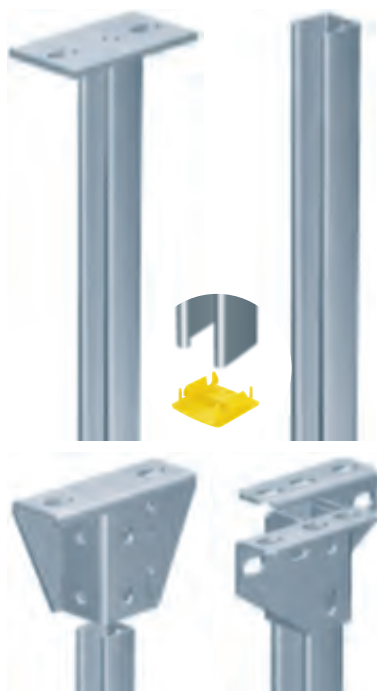

FIXATION PLAFOND

PENDARDS LOURDS GAMME 41

→ R41S



	L mm	 mm	 daN.m	Emb.	GS	HR	GC	304L	316L
P41S300	300	2,5	100	1 P	-	-	595 153	-	-
P41S400	400	2,5	100	1 P	-	-	595 163	-	-
P41S500	500	2,5	100	1 P	-	-	595 103	-	595 104
P41S600	600	2,5	100	1 P	-	-	595 173	-	-
P41S800	800	2,5	100	1 P	-	-	595 113	-	595 114
P41S1000	1000	2,5	100	1 P	-	-	595 123	-	595 124
P41S1500	1500	2,5	100	1 P	-	-	595 133	-	595 134
P41S2000	2000	2,5	100	1 P	-	-	595 143	-	595 144
R41S3000 E20	3000	2	-	3 M	343 750	343 756	343 753	343 758	343 754
R41S3000 E25	3000	2,5	-	3 M	345 200	-	345 203	-	345 204
PFN41S	-	-	100	10 P	595 360	349 720	-	-	595 364
SU41	-	-	35	10 P	595 340	-	-	-	-
PFRM	-	-	-	10 P	561 110	-	561 113	-	-
PVC									
EP41	-	-	-	50 P	348 577	-	-	-	-




P31 25 à P31 100
↳ 50 -> 600 mm



CF 30 à CF 150
↳ 50 -> 600 mm




MONTAGE

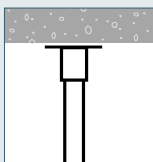

FIXATION

PFN41S

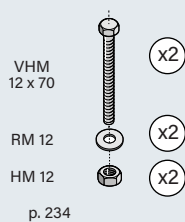


SU41




DIMENSIONS


R41S

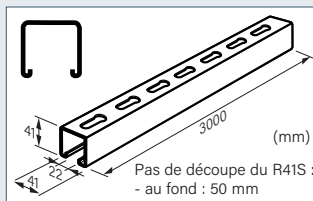


P41S

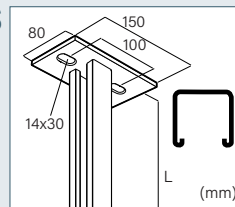


PFN41S

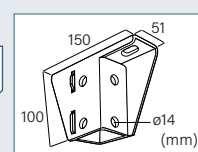

SU41

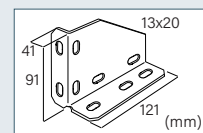

PFRM

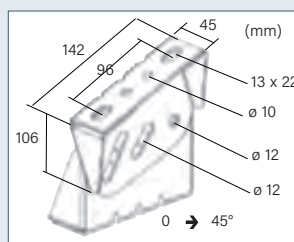

EP41



Vis : - 1 point de fixation jusqu'à la largeur 200 mm incluse
- 2 points de fixation à partir de la largeur 300 mm
FS41 : 1 FS41 pour la largeur 50, 2 FS41 à partir de la largeur 100



Visserie
p. 234-235