




FIXATION PLAFOND



PENDARDS LOURDS GAMME 41



→ R41S

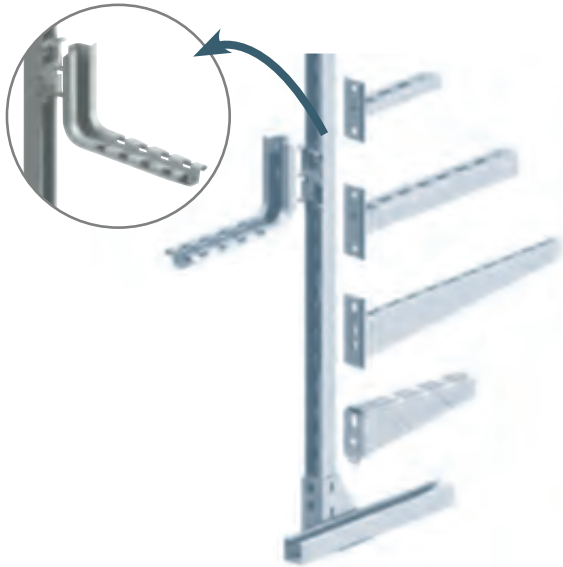


	L mm	Δ mm	daN.m	Emb.	GS	HR	GC	Emb.	304L	316L
R41S3000 E20	3000	2	-	3 M	343 750	343 756	343 753	-	343 758	343 754
R41S3000 E25	3000	2,5	-	3 M	345 200	-	345 203	-	-	345 204
				Emb	PVC			Emb		
EP41	-	-	-	50 P	348 577	-	-	50 P	-	-
				Emb	GS		GC	Emb	304L	316L
CSN 100	178	-	130	5 P	556 100	-	556 103	20 P	556 108	556 104
CSN 150	228	-	110	5 P	556 110	-	556 113	20 P	556 118	556 114
CSN 200	278	-	85	5 P	556 120	-	556 123	20 P	556 128	556 124
CSN 300	378	-	73	20 P	556 130	-	556 133	20 P	556 138	556 134
CSN 400	478	0,7	56	10 P	556 140	-	556 143	-	-	-
CSN 450	528	0,9	50	8 P	556 150	-	556 153	-	-	-
INTERFAS	100	-	-	10 P	557 800	-	557 803*	-	-	-
				daN	Emb		GC	Emb		316L
C41S150	150	-	500	20 P	-	-	595 013	1 P	-	595 014
C41S200	200	-	450	20 P	-	-	595 023	1 P	-	595 024
C41S300	300	-	340	16 P	-	-	595 033	1 P	-	595 034
C41S400	400	-	270	12 P	-	-	595 043	1 P	-	595 044
C41S500	500	-	270	8 P	-	-	595 053	1 P	-	595 054
C41S600	600	-	220	8 P	-	-	595 063	1 P	-	595 064
				H mm	Emb	GS	HR	Emb		316L
CB400	400	99	150	10 P	350 850	350 866	-	10 P	-	350 854
CB500	500	136,9	200	10 P	350 860	350 876	-	10 P	-	350 864
CB600	600	136,9	160	10 P	350 870	350 806	-	10 P	-	350 874

  


* ZnL

MONTAGE

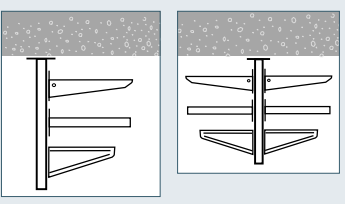

FIXATION

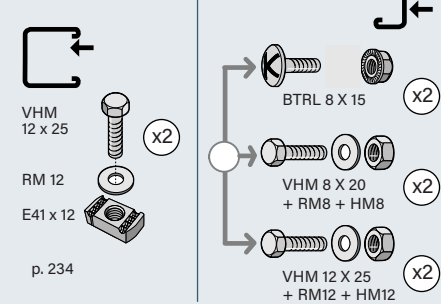


FIXATION DU CHEMIN DE CÂBLE



p. 200 et 220


DIMENSIONS

R41S

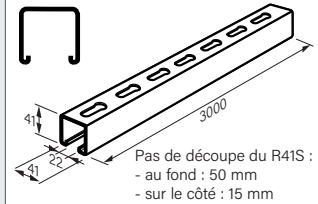


Pas de découpe du R41S :
- au fond : 50 mm
- sur le côté : 15 mm


C41S

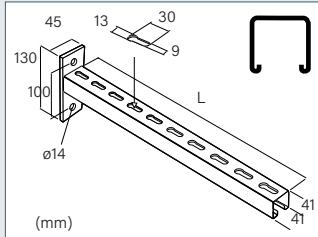


CSN

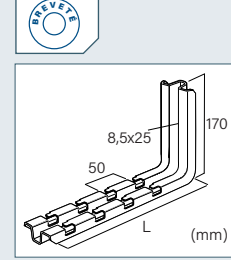

INTERFAS

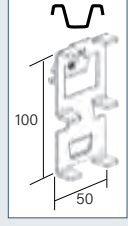

CB

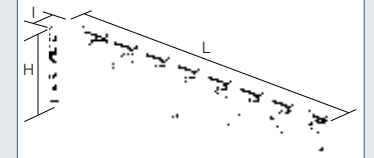

Vis : - 1 point de fixation jusqu'à la largeur 200 mm incluse
- 2 points de fixation à partir de la largeur 300 mm
FS41 : 1 FS41 pour la largeur 50, 2 FS41 à partir de la largeur 100

Visserie
p. 234-235

Consoles CRP
p. 200