

FIXATIONS DIVERSES

POSE AU SOL

→ RAILS RCSN



013 150



CF 30 à CF 105
100 -> 600 mm




FAST LOT
FAST ASSEMBLING SYSTEM

Peut également être fixé :


- au mur
- sur remontée verticale
- en balancelle, prendre un RCSN de 100 mm supérieur à la largeur du chemin de câbles

	Charge (daN)	L (mm)	Emb.	GS	GC	304L	316L
RCSN150	100	150	10 P	013 150	013 153	-	013 154
RCSN200	100	200	10 P	013 200	013 203	-	013 204
RCSN300	100	300	10 P	013 300	013 303	-	013 304
RCSN400	100	400	10 P	013 400	013 403	-	013 404
RCSN500	100	500	10 P	013 500	013 503	-	013 504
RCSN600	100	600	10 P	013 600	013 603	-	013 604
RCSN700	100	700	15 P	013 700	-	-	-
RCSN1000	100	1000	1 P	013 010	013 013	-	013 014
RCSN2000	100	2000	1 P	013 020	013 023	013 028	013 024
RCSN3000	100	3000	1 P	013 030	013 033	013 038	013 034

MONTAGE

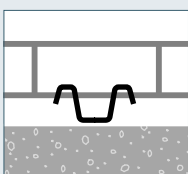

FIXATION DU CHEMIN DE CÂBLES

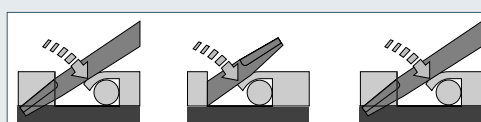

Recourber la patte d'accrochage sur le fil

DIMENSIONS

