


# ÉCLISSES POUR ÉCHELLES À CÂBLES

## → ÉCLISSES ENCLIQUETABLES

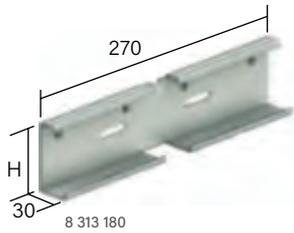

H (mm) Emb. **GS** Emb. **GC**

<b>SV GLO4/60</b>	60	10 P	8 313 180	30 P	8 363 180
<b>SV GLO4/100</b>	100	30 P	8 313 280	20 P	8 363 280

## → ÉCLISSES CHANGEMENT DE PLAN ENCLIQUETABLES



H (mm) Emb. **GS** **GC**

<b>GKL GLO4/60</b>	60	20 P	8 313 150	8 363 150
<b>GKL GLO4/100</b>	100	10 P	8 313 250	8 363 250

## → ÉCLISSES DE DÉRIVATION ENCLIQUETABLES



H (mm) Emb. **GS** Emb. **GC**

<b>WKV GLO4/60</b>	60	10 P	8 313 130	25 P	8 363 130
<b>WKV GLO4/100</b>	100	8 P	8 313 230	8 P	8 363 230

## → ÉCLISSES PLIABLES




Montage avec vis et écrou GL04 M6 (p. 240)

H (mm) Emb. **GS** Emb. **GC**

<b>HFEV GLO4/60</b>	60	80 P	8 313 140	70 P	8 363 140
<b>HFEV GLO4/100</b>	100	10 P	8 313 240	25 P	8 363 240

## → ÉCLISSES COMPAS

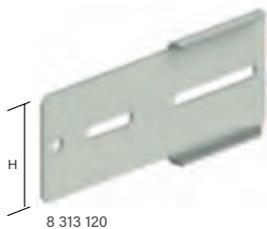


Montage avec vis et écrou GL04 M6 (p. 240)

H (mm) Emb. **GS** Emb. **GC**

<b>VKV GLO4/60</b>	60	50 P	8 313 120	10 P	8 363 120
<b>VKV GLO4/100</b>	100	50 P	8 313 220	50 P	8 363 220

## → PLAQUE PLIABLE MULTI-FONCTIONS

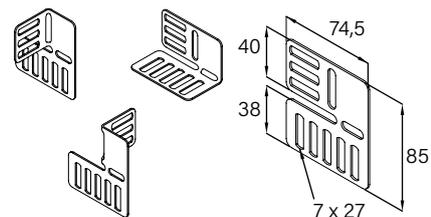

Montage avec vis et écrou GL04 M6 (p. 240)

Emb. **GS**

<b>KLUVB</b>	50 P	340 183
--------------	------	---------

## → PLATINE DE MONTAGE UNIVERSELLE



350 156

Emb. **GC**

<b>GL04</b>	1 P	350 156
-------------	-----	---------

## → PLATINE DE MONTAGE UNIVERSELLE



8 362 020

Emb. **GC**

<b>EAC</b>	1 P	8 362 020
------------	-----	-----------