


Electrak® 26 powertrack / underfloor busbar system

dual circuit system (dark green)

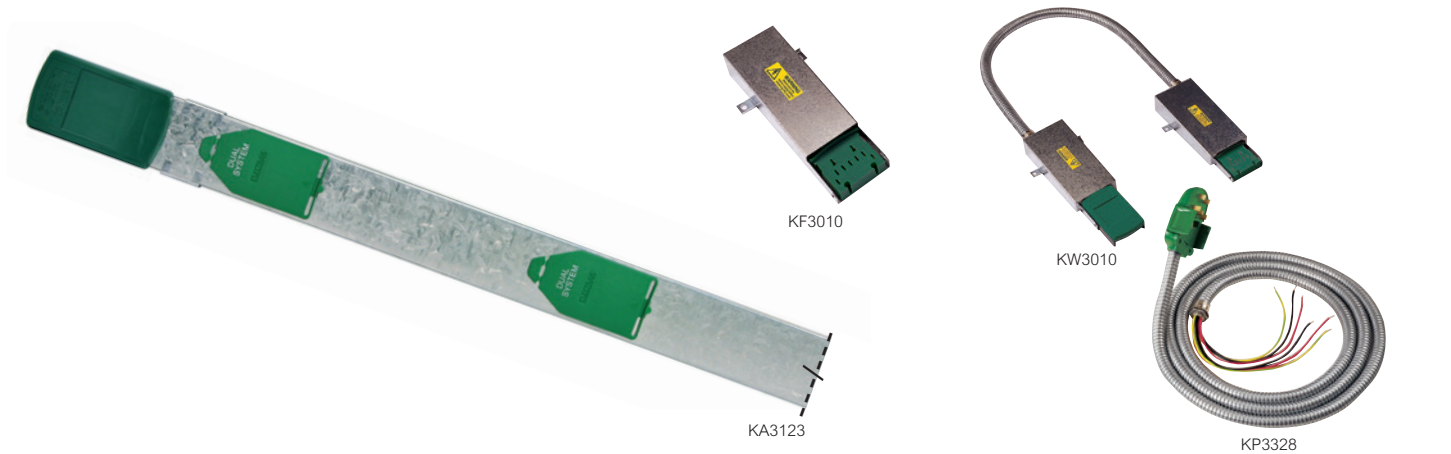

 Selection charts **p. 8-9**
Dimensions and technical information **p. 18-23**

Approved to ISO 9001
Conforms to BS EN 61534-22. Fully complies with the requirements of BS 7671
A compact system that can be installed in floor voids as low as 48 mm

Pack	Cat. Nos.	Track system components
		The dual powertrack system has both standard and low noise / clean earth systems incorporated
		Electrak 26 dual circuit track lengths
		Track lengths fit together using the integral connectors on each length
		Track lengths should always be secured using the integral floor fixing brackets
		300 mm socket centres
1	KA3123	1.2 m, 4 outlets, 2 floor fixing brackets
1	KA3183	1.8 m, 6 outlets, 2 floor fixing brackets
1	KA3243	2.4 m, 8 outlets, 2 floor fixing brackets
1	KA3363	3.6 m, 12 outlets, 3 floor fixing brackets
		Track feed unit
1	KF3010	With two 25 mm diameter holes suitable for MICC, armoured cables or single core cables in conduit
		Flexible interlinks
		Can be used to overcome obstructions or as corners where required
1	KW3000	Excluding cables and conduit
1	KW3010	1.2 m flexible metal conduit
1	KW3020	2.4 m flexible metal conduit
		Special fixing brackets
		Required when track is raised off surface level
		Brackets raise track by 21 mm and should be spaced 600 mm apart
1	DZ1210	For fitting under track body and track feed
1	DZ1230	For fitting under integral track connectors

Pack	Cat. Nos.	Tap-off units
		Tap-off length is determined by the cable and not the conduit length, e.g. a 3 m tap-off has 3 m of cable and 2.6 m of flexible metal conduit ¹
		Tap-off units in excess of 3 m should only be used if they contain a fuse or if the powertrack is protected by a protective device not exceeding 32 A
		Standard 32 A unfused - 543-7 high integrity
		16 mm Ø, L, N, PE
1	DP1332	3 m
1	DP1532	5 m
		Standard 13 A fused - 543-7 high integrity
		16 mm Ø, L, N, PE
1	DP1327	3 m
1	DP1527	5 m
		Standard 13 A fused
		16 mm Ø, L, N, PE
1	DP1313	3 m
1	DP1513	5 m
		Low noise / clean earth 32 A unfused - 543-7 high integrity
		16 mm Ø, CE, L, N, PE
1	JP2332	3 m
1	JP2532	5 m
		Low noise / clean earth 13 A fused - 543-7 high integrity
		16 mm Ø, CE, L, N, PE
1	JP2327	3 m
1	JP2527	5 m
		Low noise / clean earth 13 A fused
		16 mm Ø, CE, L, N, PE
1	JP2313	3 m
1	JP2513	5 m
		Dual circuit 32 A unfused - 543-7 high integrity
		20 mm Ø, CE, L1, N1, L2, N2, PE
1	KP3328	3 m
1	KP3528	5 m

¹ : Tap-offs are supplied as standard with flexible metal conduit
For alternative wiring solutions, contact us on +44 (0) 370 608 9020