


Intersoc-R™ desk modules

electrical supply

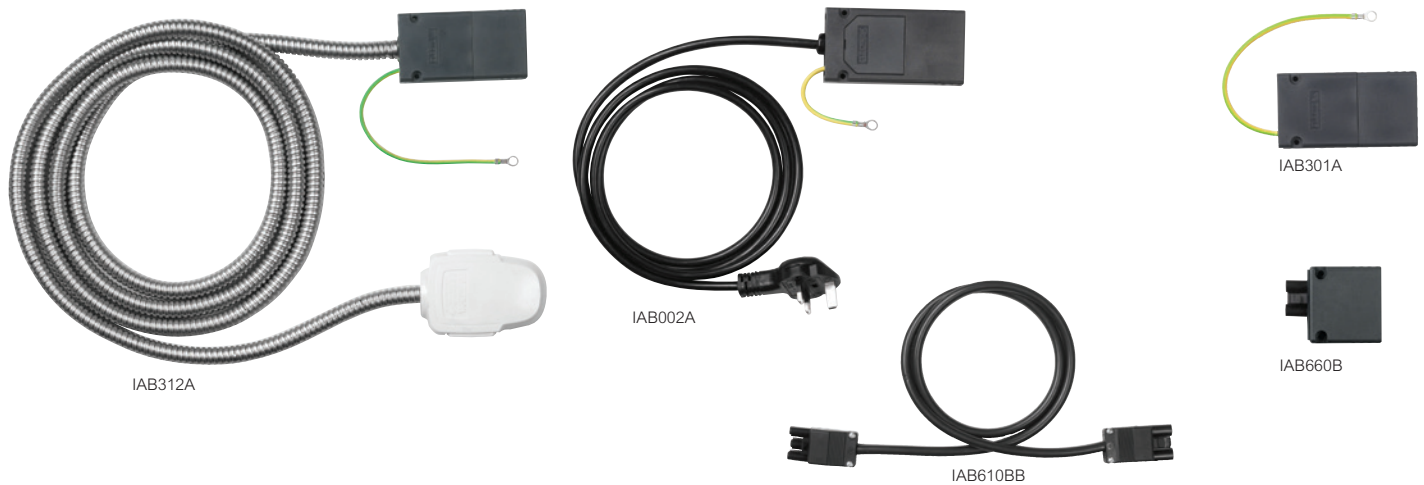

Dimensions and technical information p. 44-47

Intersoc-R features fast modular connection with push-fit auto lock mechanism, safe shuttered electrical connections and a robustly designed rigid joint between modules. Available in standard and clean earth versions
Independently approved by Intertek. Complies with BS 5733 and the relevant parts of BS 1363 part 2. Manufactured in an approved ISO 9001 facility. Meets the requirements of BS 7671 for high integrity earthing (section 543:7)

Pack	Cat. Nos.	32 A pre-wired feed modules
		Standard earth tap-offs (E24 - White tap-off)
1	IAB311A	3 m unfused metal tap-off Cat. No. DP1332
1	IAB312A	5 m unfused metal tap-off Cat. No. DP1532
1	IAB315A	3 m 13 A fused 543:7 metal tap-off Cat. No. DP1327
1	IAB316A	5 m 13 A fused 543:7 metal tap-off Cat. No. DP1527
		Low noise / clean earth tap-offs (E25 - Green tap-off)
1	IAC311A	3 m unfused metal tap-off Cat. No. JP2332
1	IAC312A	5 m unfused metal tap-off Cat. No. JP2532
1	IAC315A	3 m 13 A fused 543:7 metal tap-off Cat. No. JP2327
1	IAC316A	5 m 13 A fused 543:7 metal tap-off Cat. No. JP2527
		Auxiliary earth tap-offs (E28 - Red tap-off)
1	IAF311A	3 m unfused metal tap-off Cat. No. YP5332
1	IAF312A	5 m unfused metal tap-off Cat. No. YP5532
1	IAF315A	3 m 13 A fused 543:7 metal tap-off Cat. No. YP5327
1	IAF316A	5 m 13 A fused 543:7 metal tap-off Cat. No. YP5527

Pack	Cat. Nos.	32 A re-wirable feed modules
1	IAB301A	Standard earth (for flexible conduit)
1	IAC301A	Low noise (for flexible conduit)

Pack	Cat. Nos.	32 A feed units with in-built Neutrik connectors
1	IAB301E	Standard earth
1	IAC301E	Low noise

Pack	Cat. Nos.	32 A tap-offs pre-wired to Neutrik connectors (NAC3 - 2FC)
		Standard earth tap-offs (E24)
1	IAB311E	3 m unfused metal tap-off Cat. No. DP1332
1	IAB312E	5 m unfused metal tap-off Cat. No. DP1532
1	IAB315E	3 m 13 A fused 543:7 metal tap-off Cat. No. DP1327
1	IAB316E	5 m 13 A fused 543:7 metal tap-off Cat. No. DP1527
		Low noise / clean earth tap-offs (E25)
1	IAC311E	3 m unfused metal tap-off Cat. No. JP2332
1	IAC312E	5 m unfused metal tap-off Cat. No. JP2532
1	IAC315E	3 m 13 A fused 543:7 metal tap-off Cat. No. JP2327
1	IAC316E	5 m 13 A fused 543:7 metal tap-off Cat. No. JP2527

Pack	Cat. Nos.	16 A feed modules pre-wired to 13 A fused plug
1	IAB002A	With 2 m 1.5 mm ² cable
1	IAB003A	With 3 m 1.5 mm ² cable
1	IAB005A	With 5 m 1.5 mm ² cable
		16 A rewirable feed modules
1	IAB201A	Rewirable feed module (for cable)
		16 A feed units with in-built GST connector
1	IAB660B	Compact feed module with male GST connector
1	IAB201B	Feed module with male GST and earth bond lead
		16 A pre-wired connection leads
		13 A fused plug pre-wired to GST connector
1	IAB002B	With 2 m 1.5 mm ² cable
1	IAB003B	With 3 m 1.5 mm ² cable
1	IAB005B	With 5 m 1.5 mm ² cable
		GST to GST connection leads
1	IAB610BB	1 m length
1	IAB620BB	2 m length
1	IAB630BB	3 m length

For details of Dynamic Monitor Arms contact us on +44 (0) 370 608 9020 or visit www.legrand.co.uk

