

covers and couplers

75 → 600 mm

3 m



6379 64



6377 91

Pack	Cat. Nos.	Covers
		Width (mm)
		PVC
24	6377 60	75
24	6377 61	100
18	6377 62	150
12	6377 63	200
12	6377 64	300
12	6377 65	400
12	6379 63	500
12	6379 64	600

 
Pack	Cat. Nos.	Couplers
		Couplers (mm)
		PVC
20	6377 90	For 75 to 150 x 50
20	6377 91	For 200 to 400 x 50
20	6378 90	For 75 to 150 x 75
20	6378 91	For 200 to 400 x 75
20	6379 90	For 200 to 600 x 100
		Hinged couplers (mm)
20	6377 93	For width 75 to 150
20	6379 93	For width 200 to 600

covers and couplers

technical information

Covers

Dimensions




A (mm)	B (mm)	C (mm)	D (mm)	Length (mm)
75	15-6	56-6	1-2	3 000
100	15-6	81-6	1-2	3 000
150	15-9	131-6	1-5	3 000
200	23-9	171-6	2	3 000
300	25-3	271-6	2-5	3 000
400	25-3	371-6	2-5	3 000
500	28-1	471-6	2-8	3 000
600	28-1	571-6	2-8	3 000

Couplers

Dimensions

Cat. Nos. 6377 90 and 6378 90

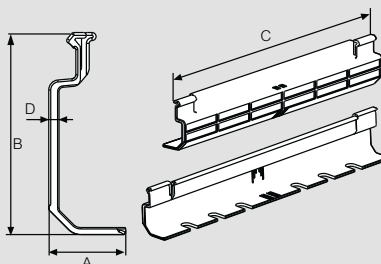


Depth (mm)	A (mm)	B (mm)	C (mm)	D (mm)
50	27	45-9	275	3-6
75	27	70-9	275	3-6

Fixing



Cat. Nos. 6377 91, 6378 91 and 6379 90

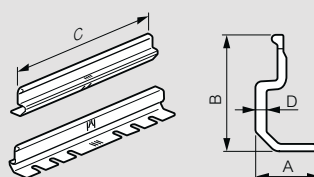


Depth (mm)	A (mm)	B (mm)	C (mm)	D (mm)
50	38-3	45-4	300	5
75	38-8	69-8	350	7-5
100	38-8	92-8	450	7-5

Fixing



Hinged Cat. Nos. 6377 93 and 6379 93

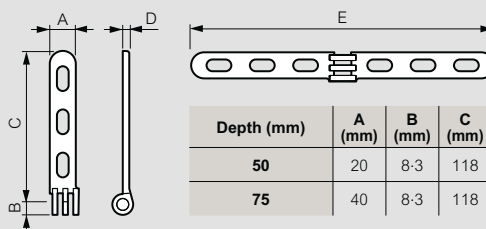

Depth (mm)	A (mm)	B (mm)	C (mm)	D (mm)	E (mm)
50	20	8-3	118	5	244-3
75	40	8-3	118	5	244-3