

fittings

50 → 100 mm

75 → 600 mm



6377 15



6377 17

Pack	Cat. Nos.	Inside 90° risers
		Supplied with covers
		PVC
		Width x Depth (mm)
4	6377 05	For 75 x 50
4	6377 15	For 100 x 50
4	6377 25	For 150 x 50
2	6377 35	For 200 x 50
2	6377 45	For 300 x 50
1	6377 55	For 400 x 50
4	6378 05	For 75 x 75
4	6378 15	For 100 x 75
4	6378 25	For 150 x 75
2	6378 35	For 200 x 75
2	6378 45	For 300 x 75
1	6378 55	For 400 x 75
1	6379 05	For 200 x 100
1	6379 15	For 300 x 100
1	6379 25	For 400 x 100
1	6379 35	For 500 x 100
1	6379 45	For 600 x 100


Pack	Cat. Nos.	Outside 90° risers
		Supplied with covers
		PVC
		Width x Depth (mm)
4	6377 07	For 75 x 50
4	6377 17	For 100 x 50
4	6377 27	For 150 x 50
2	6377 37	For 200 x 50
2	6377 47	For 300 x 50
1	6377 57	For 400 x 50
4	6378 07	For 75 x 75
4	6378 17	For 100 x 75
4	6378 27	For 150 x 75
2	6378 37	For 200 x 75
2	6378 47	For 300 x 75
1	6378 57	For 400 x 75
1	6379 07	For 200 x 100
1	6379 17	For 300 x 100
1	6379 27	For 400 x 100
1	6379 37	For 500 x 100
1	6379 47	For 600 x 100

fittings

technical information

Inside 90° risers

Dimensions and fixing

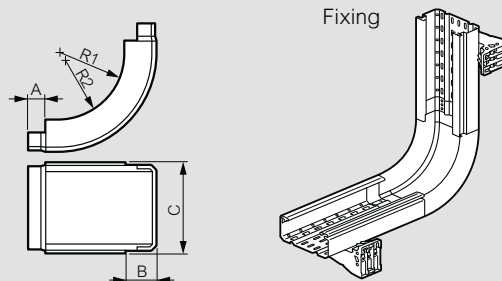


Width (mm)	A (mm)	C (mm)	R1 (mm)	R2 (mm)
75	52	68	150	200
100	52	93	150	200
150	52	142	150	200
200	52	190	150	200
300	52	289	150	200
400	52	388	150	200
500	52	488	150	200
600	52	587	150	200

B = 50, 75 or 98 mm

Outside 90° risers

Dimensions and fixing

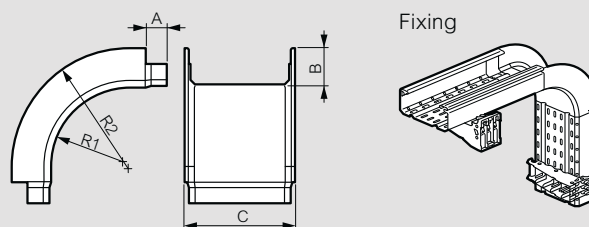

Width (mm)	A (mm)	C (mm)	R1 (mm)	R2 (mm)
75	52	68	150	200
100	52	93	150	200
150	52	142	150	200
200	52	190	150	200
300	52	289	150	200
400	52	388	150	200
500	52	488	150	200
600	52	587	150	200

B = 52, 75 or 98 mm