


Salamandre® distribution trunking accessories and fasteners

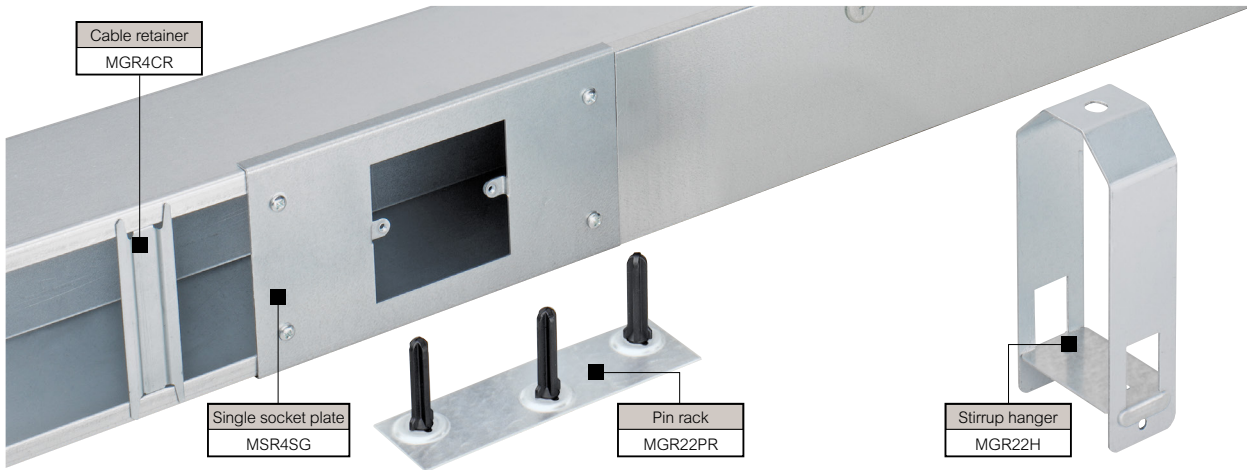

Selection chart (p. 8-9)
 Order information (p. 10)
 Standards and quality assessment (p. 20)
 Dimensions and technical information (p. 28)

Accessories

Pack	Cat. Nos.	Description	Image	
10	MGR2CR	Cable retainers 50 mm wide		
10	MGR3CR	75 mm wide		
10	MGR4CR	100 mm wide		
10	MGR6CR	150 mm wide		
10	MGR9CR	225 mm wide		
10	MGR12CR	300 mm wide		
1	MGR Z PR	Pin racks 1 compartment Multi-compartment trunking Order per compartment		
10	EL	Earth link Fastenings not supplied		
1	MGR22H	Stirrup hangers Hole for M10 rod		
1	MGR33H			50 mm wide. 50 mm max. depth
1	MGR44H			75 mm wide. 75 mm max. depth
1	MGR66H			100 mm wide. 100 mm max. depth
1	MGR9 Z H	150 mm wide. 150 mm max. depth		
1	MGR12 Z H	225 mm wide (not illustrated)		
1	MGR12 Z H	300 mm wide (not illustrated)		
10	MGR Z OH	Overhead hanger Hole for M10 rod Trunking must be fixed to base of hanger		
1	MGR2PART	Loose partitions – 3 m		
1	MGR3PART			50 mm deep
1	MGR4PART			75 mm deep
1	MGR6PART			100 mm deep
1	MGR9PART			150 mm deep
1	MGR12PART			225 mm deep

Accessories (continued)

Pack	Cat. Nos.	Description	Image	
1	T206	PVC edging strip For fitting on to top edge of partition 10 m strip		
1	MSR4SG	Socket plates Not applicable to IP4X Only available in screwfix or tamperproof		
1	MSR6SG			Single 100 mm wide
1	MSR9SG			150 mm wide
1	MSR12SG			225 mm wide
1	MSTR4TS	300 mm wide		
1	MSTR6TS	Twin 100 mm wide		
1	MSTR9TS	150 mm wide		
1	MSTR12TS	225 mm wide		
1	MSTR12TS	300 mm wide		
100	ETCLIP	Fasteners M5 clip nut		
10	RTB1	Diecast turnbuckle for lid width up to 150 mm		
10	RTB2	Diecast turnbuckle for lid width 225 mm and above		
100	T301	Screwfix M5 x 9		
100	T304	Tamperproof screwfix (M5 TORX) M5 x 8		
100	T306	M5 Hex nut		
1	TX25	Screwdriver for tamperproof screwfix		

Key : Z = trunking size code
 Replace Z with the relevant code (see p. 10)
 Note:
 For stirrup hangers (where shown), insert ONLY THE SECOND NUMBER from the relevant trunking size code