


Salamandre® lighting trunking

lengths, lids and fittings

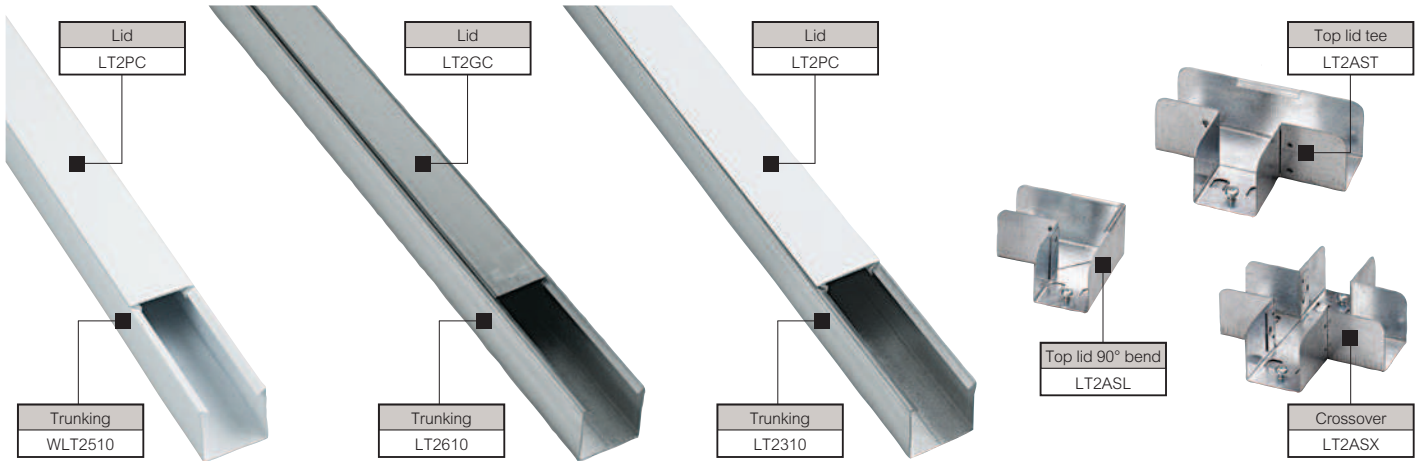

Selection chart (p. 17)
Dimensions and technical information (p. 31)

A 'clip-in' lid trunking system for fast installation
Available with a choice of 3 lids in plastic or galvanised finishes
For white powder coated finish to RAL 9003 product code starts WLT2,
for pre-galvanised code starts LT2
All lighting trunking fittings have friction grip to aid quick installation

Pack	Cat. Nos.	Trunking lengths
		Lids and couplers not included
		White
		Nominal steel thickness 1.0 mm
1	WLT2510	50 mm x 50 mm – 5 m
		Galvanised
		Nominal steel thickness 1.0 mm
1	LT2310	50 mm x 50 mm – 3 m
1	LT2410	50 mm x 50 mm – 4 m
1	LT2510	50 mm x 50 mm – 5 m
1	LT2610	50 mm x 50 mm – 6 m

Pack	Cat. Nos.	Lids
		Lids – galvanised 2 m length
1	LT2GC	Standard width
1	WLT2GC	Standard width – painted
		Lid – white plastic 2 m length
1	LT2PC	Standard width

Pack	Cat. Nos.	Fittings
		Long coupler
1	LT2C	50 mm x 50 mm
		Top lid 90° bends
1	LT2ASL	50 mm x 50 mm
1	WLT2ASL	50 mm x 50 mm – white
		Inside lid 90° bends
1	LT2BSL	50 mm x 50 mm
1	WLT2BSL	50 mm x 50 mm – white
		Outside lid 90° bends
1	LT2CSL	50 mm x 50 mm
1	WLT2CSL	50 mm x 50 mm – white
		Top lid 45° bends
1	LT2AL	50 mm x 50 mm
1	WLT2AL	50 mm x 50 mm – white
		Inside lid 45° bends
1	LT2BL	50 mm x 50 mm
1	WLT2BL	50 mm x 50 mm – white
		Outside lid 45° bends
1	LT2CL	50 mm x 50 mm
1	WLT2CL	50 mm x 50 mm – white
		Top lid tees
1	LT2AST	50 mm x 50 mm
1	WLT2AST	50 mm x 50 mm – white
		Inside lid tees
1	LT2BST	50 mm x 50 mm
1	WLT2BST	50 mm x 50 mm – white
		Outside lid tees
1	LT2CST	50 mm x 50 mm
1	WLT2CST	50 mm x 50 mm – white
		Crossovers
1	LT2ASX	50 mm x 50 mm
1	WLT2ASX	50 mm x 50 mm – white