
 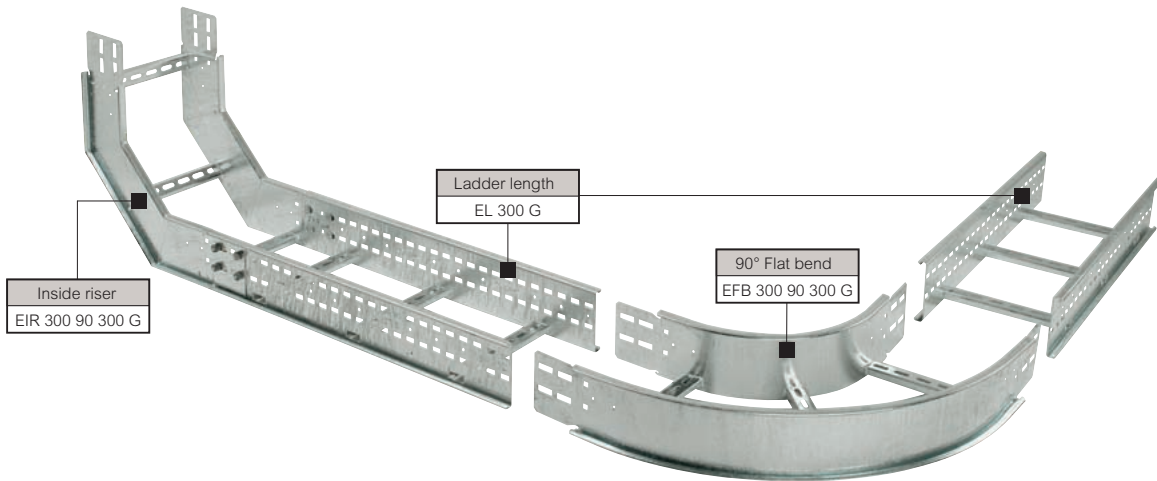


Swifts® extra heavy duty (Emerald) cable ladder

lengths and fittings




Selection chart (p. 10-11)
 Dimensions and technical information : lengths (p. 36) ; coupler sets (p. 38-45) ; fittings (p. 46-73)
 Design notes (p. 112)
 Loading graphs (p. 34)

When connecting fittings to straight lengths, use fastener sets (see below)


Rung spacing : 300 mm between centres
 Standard radius for fittings : 300 and 600 mm

Pack	Cat. Nos.	Straight lengths – 3 m
1	EL 150 F	150 mm width
1	EL 300 F	300 mm width
1	EL 450 F	450 mm width
1	EL 600 F	600 mm width
1	EL 750 F	750 mm width
1	EL 900 F	900 mm width


6 m lengths available on special request
 For technical information, see p. 36

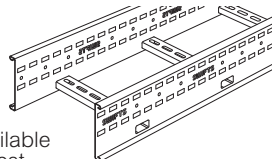

Pack	Cat. Nos.	Coupler sets
1	EC F	Straight length to straight length Supplied in pairs, with fasteners (8 per coupler) Use to couple straight lengths to straight lengths For technical information, see p. 38-39

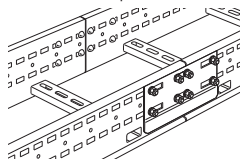

1	EFC F	Fitting to fitting Supplied in pairs, with fasteners (8 per coupler) Use to couple fitting to fitting For technical information, see p. 44-45
---	-------	---

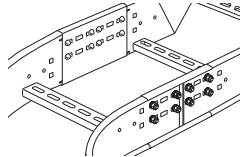

Pack	Cat. Nos.	Fastener sets
50	LFGM10P50	Comprise M10 coach bolt and flange nut
50	LFSM10P50	Hot dip galvanised
		Stainless steel




Pack	Cat. Nos.
1	EFB WArF
1	EIR WArF
1	EOR WArF

Fittings


Flat bends

For technical information, see p. 46-49

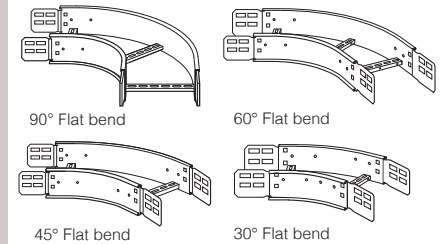

Inside risers

For technical information, see p. 52, 55, 58, 61

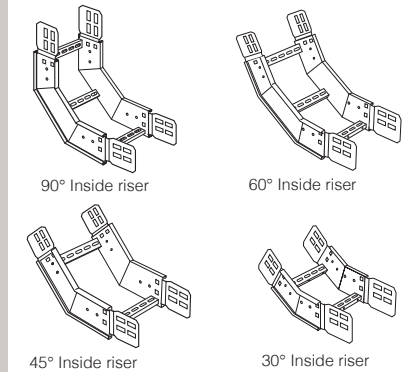

Outside risers

For technical information, see p. 52, 55, 58, 61

