
 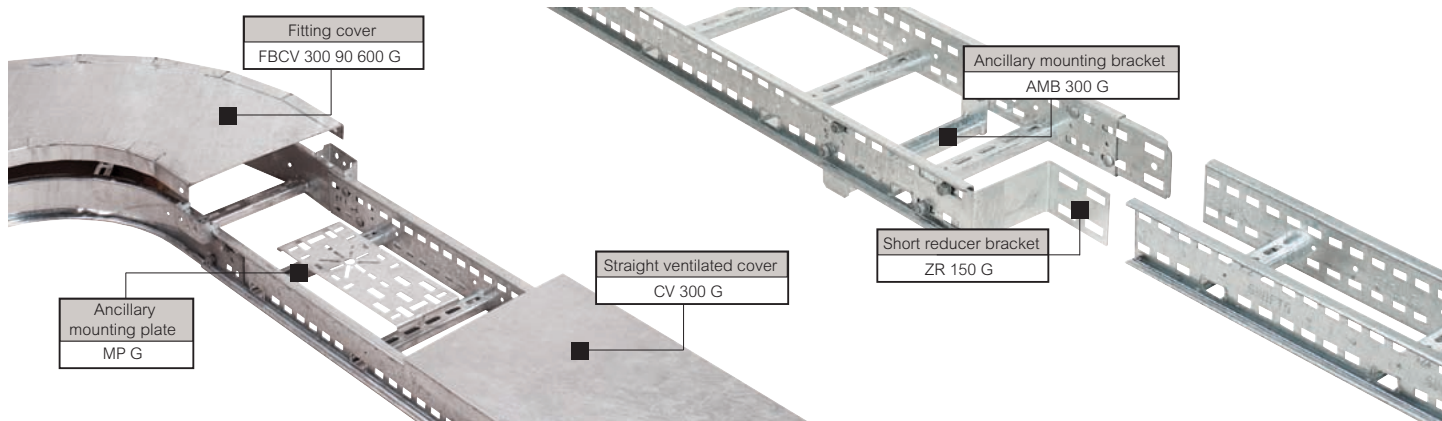


Swifts® cable ladder ancillary items (continued) and covers

Topaz, Sapphire and Emerald



Dimensions and technical information (p. 90-98)

Pack	Cat. Nos.	Ancillary items (continued)	Pack	Cat. Nos.	Covers
1	ZR YF PR YF ER YF	Short reducer brackets Supplied singly with fasteners Use to form a reducer on site Straight reducer – use in pairs Offset reducer – use singly with straight coupler $Y = W - K$ $Y = \frac{W - K}{2}$ W = main ladder mm K = reduced ladder mm To calculate (Y) for straight reducers and offset reducers (see p. 90) For technical information, see p. 90	1	CV W F	Supplied with clips and fasteners Covers for both closed and ventilated installations are common (except when using inside and outside risers, see below) 600 mm wide and above are overlap jointed for rigidity For technical information, see p. 95-98 Straight covers – 3.0 m Available in 150-900 mm widths Example : To cover a 300 mm wide Z, P or E ladder length with a straight hot dip galvanised cover, ordering code for cover = CV 300 G
1	AMB W F	Ancillary mounting bracket Supplied singly with bracket to ladder fasteners For technical information, see p. 91 All ladder types 	1	–	Covers for fittings (except risers) To order a cover for a fitting, (except risers) remove first letter of fitting product code (Z, P or E) and add CV before your chosen dimensions Example : Product code = PFB 300 90 600 G Cover code = FB CV 300 90 600 G
1	MP F	Ancillary mounting plate Supplied singly with bracket to ladder fasteners For technical information, see p. 92 All ladder types For rung mounting or Side rail mounting 	1	ZIRC WArF PIRC WArF EIRC WArF	Inside riser closed covers Medium duty (Topaz) Heavy duty (Sapphire) Extra heavy duty (Emerald)
1	CSB F	Cable support bracket For technical information, see p. 93 Supplied singly with fasteners Cable ties not included 	1	ZIRV WArF PIRV WArF EIRV WArF	Inside riser ventilated covers Medium duty (Topaz) Heavy duty (Sapphire) Extra heavy duty (Emerald)
			1	ZORC WArF PORC WArF EORC WArF	Outside riser closed covers Medium duty (Topaz) Heavy duty (Sapphire) Extra heavy duty (Emerald)
			1	ZORV WArF PORV WArF EORV WArF	Outside riser ventilated covers Medium duty (Topaz) Heavy duty (Sapphire) Extra heavy duty (Emerald)

Key : selecting for ancillary items and covers. Replace the letters shown in red with your choice from the following options :

W = Widths : 150, 300, 450, 600, 750, 900
 Y = Ladder width reduction A = Angle (°) : 90, 60, 45 or 30
 F = Finish : G (hot dip galvanised after manufacture),
 D (deep galvanised) S (stainless steel), E (powder coated)
 K = Narrowed width when using a reducer (mm) :
 150, 300, 450, 600, 750
 r = Radius (mm) : 300, 600