
 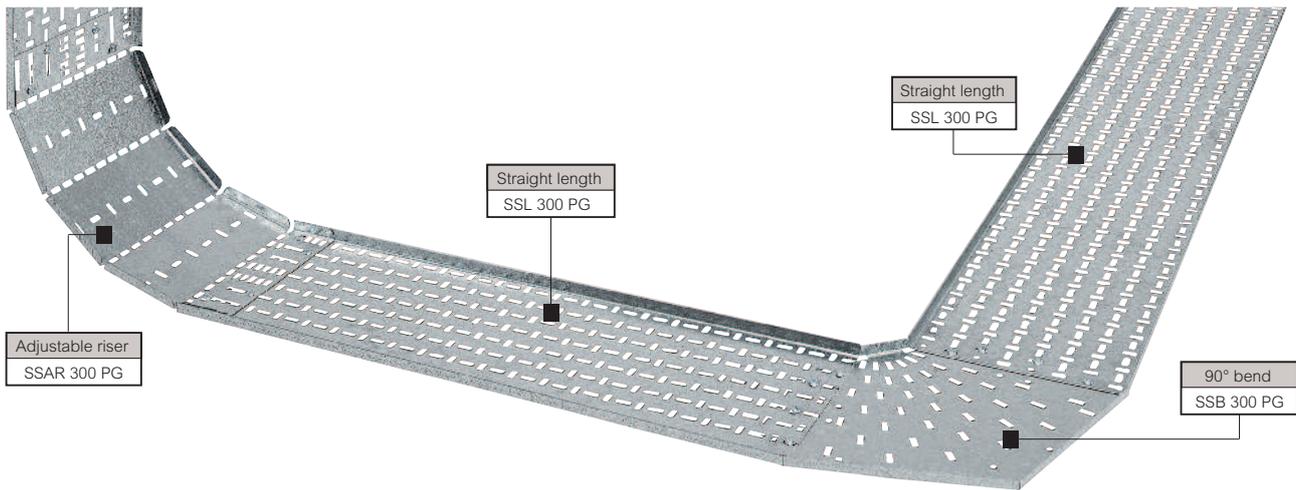


Swifts® SS light duty cable tray

lengths and fittings



Selection charts **p. 12-13**

Dimensions and technical information : lengths **p. 36** ; fittings **p. 38-45**

Design notes **p. 118**

Loading graphs **p. 36**



Pack	Cat. Nos.	Straight lengths – 3 m	
1	SSL 50 F	50	12
1	SSL 75 F	75	12
1	SSL 100 F	100	12
1	SSL 150 F	150	12
1	SSL 225 F	225	12
1	SSL 300 F	300	18

All SS straight lengths and fittings have integral couplers, no separate couplers are needed
For SS tray cut to length use fishplates across length-to-length joint, **p. 24**


For technical information, **p. 36-37**

Pack	Cat. Nos.	Fittings
1	SSB W F	90° bends For technical information, p. 38-39
1	SSB W A F	60°, 45° and 30° bends For technical information, p. 38-39

All fittings have integral fishplates
No couplers required

Pack	Cat. Nos.	Fittings (continued)
1	SSIR W F	Risers Inside and outside risers are not available in PG finish 90° inside riser For technical information, p. 40-41
1	SSIR W A F	60°, 45° and 30° inside risers For technical information, p. 40-41

Additional gauges and finishes available to special order
Contact us on +44 (0) 345 605 4333

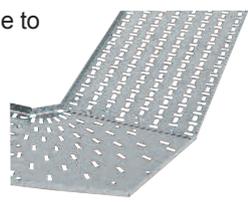

Key : selecting SS light duty fittings. Replace the letters shown in red with your choice from the following options :

W = Widths (mm) : 50, 75, 100, 150, 225, 300
A = Angle (°) : 60, 45 and 30 (90 does not need to be included in order code)
F = Finish : **G** (hot dip galvanised after manufacture)
PG (pre-galvanised), **S** (stainless steel)