

Arteor™

telephone sockets



Support frames and surround plates selection charts **p. 30, 32-35**

Mechanisms supplied with rocker plates, to be equipped with support frames (p. 30) and surround plates (p. 32 to 35)

Pack	Cat. Nos.	RJ 11 and RJ 12 sockets
		Equipped with modular Jack connector with 1/4 turn terminal for fast connection (possible looping)
		RJ 11
		1 module
		4 contacts
10	5723 00	White
10	5728 00	Magnesium
10	N 5700 56	Champagne
10	N 5710 56	Soft Alu


Pack	Cat. Nos.	Telephone sockets
		With IDC connection Conform to British Telecom
		Single master
		2 modules
10	5723 10 ¹	White
10	5728 10 ¹	Magnesium
10	N 5726 87 ¹	Champagne
10	N 5726 86 ¹	Soft Alu

Pack	Cat. Nos.	Single secondary
		1 module
5	5723 01 ¹	White
5	5728 01 ¹	Magnesium
5	N 5726 89 ¹	Champagne
5	N 5726 88 ¹	Soft Alu

1 : Not suitable for use in Republic of Ireland.

Arteor™

television sockets

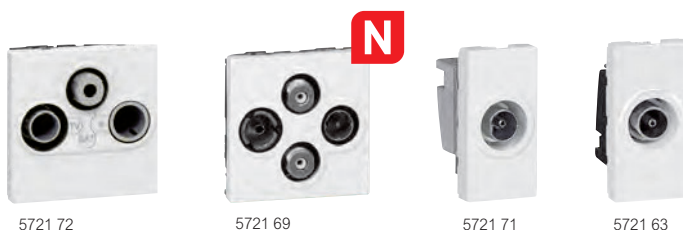

Support frames and surround plates selection charts **p. 30, 32-35**

Mechanisms supplied with rocker plates, to be equipped with support frames (p. 30) and surround plates (p. 32 to 35)

For Dvbt, Cablecast and satellite installation
UHD TV quality compatible
Classe A shielded star socket LTE ready (4G protected)
Recommended coaxial cable : 17 VATCA
Star cabling (1 socket = 1 cable to antenna, splitter or multiswitch)
Visual check of the connection
Meets EN 50083-4 and EN 50083-2 European directive
TV : male connector (∅9.5 mm) - 5-68 /120-862 MHz
R : female connector (∅9.5 mm) - 87.5-108 MHz
SAT : 'F' type connector - 950-2400 MHz

Pack	Cat. Nos.	Multi TV star sockets
		TV-R-SAT sockets
		2 modules
		Low attenuation : 1.5 dB
10	5721 72	White
10	5726 72	Magnesium
10	N 5726 91	Champagne
10	N 5726 90	Soft Alu
		TV-R-SAT-SAT sockets
		2 modules
		In1 : TV-R-SAT1 / In2 : SAT2
		Low attenuation : 1.5 dB
1	5721 69	White
1	5726 69	Magnesium
1	N 5726 93	Champagne
1	N 5726 92	Soft Alu
		TV-SAT sockets
		1 module
5	5721 67	White
5	5726 67	Magnesium
5	N 5726 95	Champagne
5	N 5726 94	Soft Alu

Pack	Cat. Nos.	Single TV star sockets
		1 module
		Low attenuation : 1 dB
		TV 9.5 mm male sockets
10	5721 71	White
10	5726 71	Magnesium
10	N 5700 51	Champagne
10	N 5710 51	Soft Alu
		TV 'F' type sockets
10	5721 63	White
10	5726 63	Magnesium
10	N 5700 50	Champagne
10	N 5710 50	Soft Alu

