

Hotel equipment

Arteor wiring devices square version



5737 22




5720 57



5725 54



5722 24

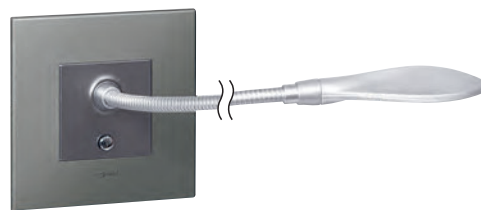

5727 57 + Magnesium surround plate 5713 12

Support frames and surround plates selection charts **p. 30, 32-35**

Mechanisms supplied with rocker plates, to be equipped with support frames (p. 30) and surround plates (p. 32 to 35)

Pack	Cat. Nos.	Lighting control
		Master switch 2 way double pole 20 AX - 250 V~ for general control : all ON / all OFF 2 modules
10	5732 84	<ul style="list-style-type: none"> <input type="radio"/> White <input type="radio"/> Magnesium <input type="radio"/> Champagne <input type="radio"/> Soft Alu
10	5737 84	
10 N	5737 89	
10 N	5737 88	
		Master push button 2 way 6 A - 250 V~ for general control : all ON/ all OFF 2 modules
10	5732 86	<ul style="list-style-type: none"> <input type="radio"/> White <input type="radio"/> Magnesium <input type="radio"/> Champagne <input type="radio"/> Soft Alu
10	5737 86	
10 N	5737 99	
10 N	5737 98	
		Switch for bed lights 2 x 2 way switch - 10 AX - 250 V~ 2 x 1 module
10	5732 94	<ul style="list-style-type: none"> <input type="radio"/> White <input type="radio"/> Magnesium <input type="radio"/> Champagne <input type="radio"/> Soft Alu
5	5737 94	
5 N	5737 63	
5 N	5737 62	
		Electric roller blinds control - 250 VA
		Double switch 10 A For direct control of a motor (mechanism with fixed positions) 2 modules
10	5732 22	<ul style="list-style-type: none"> <input type="radio"/> White <input type="radio"/> Magnesium <input type="radio"/> Champagne <input type="radio"/> Soft Alu
10	5737 22	
10 N	5737 76	
10 N	5737 75	
		Double push button 10 A For control via automatic box (N/O mechanism) 2 modules
10	5732 24	<ul style="list-style-type: none"> <input type="radio"/> White <input type="radio"/> Magnesium
10	5737 24	
		Curtain control - 250 VA
		Double switch 10 A For direct control of a motor (mechanism with fixed positions) 2 modules
10	5732 34	<ul style="list-style-type: none"> <input type="radio"/> White <input type="radio"/> Magnesium
10	5737 34	
		Double push button 10 A For control via automatic box (N/O mechanism) 2 modules
10	5732 36	<ul style="list-style-type: none"> <input type="radio"/> White <input type="radio"/> Magnesium
10	5737 36	

Arteor wiring accessories
p. 6-25

Pack	Cat. Nos.	Hotel bedroom call indicators
		Enable the resident to inform hotel staff of the room status Two settings are possible : - Do not disturb - Please clean the room 2 x 1 module
		Indicator for corridor Indicator lamp and bell push Installed in the corridor, display calls Supplied with LED
5	5720 57	<ul style="list-style-type: none"> <input type="radio"/> White <input type="radio"/> Magnesium <input type="radio"/> Champagne <input type="radio"/> Soft Alu
5	5725 57	
5 N	5737 78	
5 N	5737 77	
		Internal control unit Allows the user to select the desired setting Supplied with LED
5	5720 54	<ul style="list-style-type: none"> <input type="radio"/> White <input type="radio"/> Magnesium <input type="radio"/> Champagne <input type="radio"/> Soft Alu
5	5725 54	
5 N	5737 82	
5 N	5737 81	
		Illuminated signs Mechanisms integrating LEDs and a pivoting window that can take customised labels (printed using a simple text editor on transparent printing paper) 2 modules
		Green or red LEDs Sign with 2-state LEDs with choice of green or red configurable on the mechanism. Power level : 1 W
5	5722 24	<ul style="list-style-type: none"> <input type="radio"/> White <input type="radio"/> Magnesium <input type="radio"/> Champagne <input type="radio"/> Soft Alu
5	5727 24	
5 N	5727 46	
5 N	5727 45	
		Blue LEDs Sign with blue LEDs A choice of 2 power levels : 0.2 or 1 W
5	5722 25	<ul style="list-style-type: none"> <input type="radio"/> White <input type="radio"/> Magnesium <input type="radio"/> Champagne <input type="radio"/> Soft Alu
5	5727 22	
5 N	5727 48	
5 N	5727 47	
		Buzzers
		230 V - 1 module
10 N	5722 04	<ul style="list-style-type: none"> <input type="radio"/> White <input type="radio"/> Magnesium
5 N	5727 04	
		230 V - 2 modules
10	5722 07	<ul style="list-style-type: none"> <input type="radio"/> White <input type="radio"/> Magnesium
10	5722 47	
		Reading lights Fitted with maintenance-free LEDs LED colours : 3000 K (neutral white) 230 V power supply - energy class A Screw terminals. For installation in the bedhead Offers directional lighting. Equipped with a flexible cable so the head can swivel Built-in dimmer. Consumption 3-3 W Luminous flux 110 lumen (equivalent to 15 W incandescent) Service life 4000 hours. For installation in back box depth 40 mm min. 2 modules
1	5722 57	<ul style="list-style-type: none"> <input type="radio"/> White <input type="radio"/> Magnesium
1	5727 57	