

Synergy® white


socket outlets



Front plates : white thermostat
Terminal screws captive and backed off ready for cabling
Supplied with optional faceplate screw caps

Pack	Cat. Nos.	Double pole socket outlets 13 A - 250 V~
		Conform to BS 1363 - Part 2 : 1995 Options available as standard with red 'power on' LED indicator Red LED 'power on' upgrade pack also available (p. 54) 2 earth terminals Flush mounting back box : min. 25 mm deep Nominal plate dimensions : 86 x 86 mm
10	7300 60	1 gang – switched
10	7301 62	1 gang – switched with red rocker
10	7300 61	1 gang – switched with red LED power indicator
10	7300 64	1 gang – switched for standard and clean earth applications
10	7300 67	1 gang – switched non-standard earth pin for standard and clean earth applications
		Nominal plate dimensions : 86 x 146 mm
5	7300 70	2 gang – switched
5	7301 61	2 gang – switched with red rockers
5	7300 71	2 gang – switched with red LED power indicators
5	7300 74	2 gang – switched outboard for standard and clean earth applications
5	7300 77	2 gang – switched non-standard earth pin for standard and clean earth applications

Green locator LED pack or red power indicator pack
p. 54

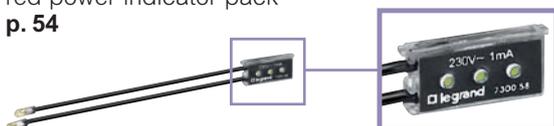

Pack	Cat. Nos.	Single pole socket outlets 13 A - 250 V~
		Conform to BS 1363 - Part 2 : 1995 Options available as standard with red 'power on' LED indicator Red LED 'power on' upgrade pack also available (p. 54) Conventional earth pin release shutter Single earth terminal Flush mounting back box : min. 25 mm deep Nominal plate dimensions : 86 x 86 mm
10	7300 66	1 gang – switched Nominal plate dimensions : 86 x 146 mm
5	7300 76	2 gang – switched
		Unswitched and key switched socket outlets 13 A - 250 V~ Conform to BS 1363 - Part 2 : 1995 Optional red LED 'power on' upgrade pack available (p. 54) (not applicable to key switched sockets) 2 earth terminals Flush mounting back box : min. 25 mm deep Nominal plate dimensions : 86 x 86 mm
10	7300 65	1 gang – unswitched Nominal plate dimensions : 86 x 146 mm
5	7300 75	2 gang – unswitched
1	8200 74	2 gang single socket with DP key switch ¹

1 : Flush mounting back box : min. 35 mm deep

Flush and surface mounting back boxes **p. 55**

