

surface mounting moulded back boxes

flush mounting steel back boxes




7364 06



7364 07




0891 10

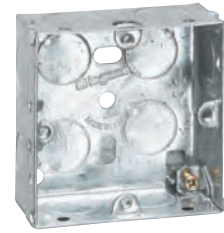

0891 13



 
 
 
 
 
 
7364 11

 
 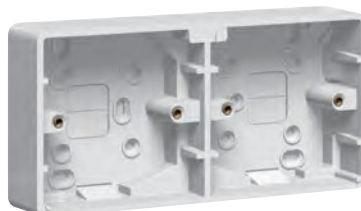

 
 
 
 
 




7364 13



0891 11

Pack	Cat. Nos.	Surface mounting moulded boxes - thermoset
		<p>Conform to BS 5733 Material : white thermoset Mini trunking knockouts located around periphery of boxes</p> <p>Dimensions : 1 gang - 86 x 86 mm 2 gang - 86 x 146 mm</p>
		<p>Depth 16 mm</p>
10	7364 03	<p> 1 gang With earth terminal</p>
		<p>Depth 35 mm</p>
10	7364 06	<p> 1 gang</p>
5	7364 10	<p> 2 gang</p>
5	7364 13	<p> 2 x 1 gang</p>
		<p>Depth 47 mm</p>
10	7364 07	<p> 1 gang</p>
5	7364 11	<p> 2 gang</p>

Pack	Cat. Nos.	Flush mounting back boxes - steel
		<p>Conform to BS 4662 Material : galvanised steel Top, side and back knockout entries according to type of box</p>
		<p>Depth 16 mm</p>
100	0891 09	<p> 1 gang with 1 fixed lug, 1 adjustable lug and 1 earth terminal</p>
		<p>Depth 25 mm</p>
50	0891 10	<p> 1 gang with 3 fixed lugs, 1 adjustable lug and 1 earth terminal</p>
10	0891 11	<p> 2 gang with 1 fixed lug, 1 adjustable lug and 1 earth terminal</p>
		<p>Depth 35 mm</p>
50	0891 13	<p> 1 gang with 3 fixed lugs, 1 adjustable lug and 1 earth terminal</p>
40	0891 14	<p> 2 gang with 1 fixed lug, 1 adjustable lug and 1 earth terminal</p>
40	0891 40	<p> Dual box with 2 earth terminals Accepts 2 single gang accessories</p>
		<p>Depth 48 mm</p>
25	0891 17	<p> 1 gang with 3 fixed lugs, 1 adjustable lug and 1 earth terminal</p>
20	0891 18	<p> 2 gang with 1 fixed lug, 1 adjustable lug and 1 earth terminal</p>

Pack	Cat. Nos.	Architrave back boxes
		<p>Depth 26 mm</p>
5	7364 40	<p> Dimensions : 82 x 28 mm</p>
5	7364 41	<p> Dimensions : 142 x 28 mm</p>