


LB PLUS straight lengths – Type A

straight lengths 25-63 A



75160102

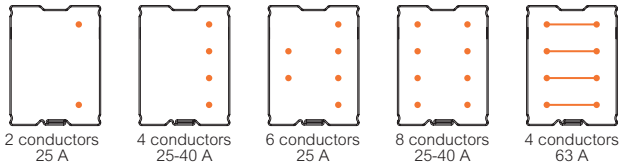

Selection chart p. 6-7
Technical data p. 12
Dimensions and technical information p. 14-15

Pack	Cat. Nos.	Straight lengths – Type A
		Rigid galvanised steel casing 3 m maximum distance between suspension brackets Conductors insulated with self-extinguishing plastic (IEC 60695-2-12 and V0 according to UL94) Standard tap-off outlets with captive IP 55 plug-outlet covers Protection index : IP 55 Impact resistance : IK 07
1	75150101	252 with 2 x 25 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 25 2 3-0 2 3-00
1	75160101	254 with 4 x 25 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 25 4 3-0 2 3-10
1	75160102	254 with 4 x 25 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 25 4 3-0 4 3-20
1	75170101	256 with 6 x 25 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 25 6 3-0 2 + 2 3-65
1	75180101	258 with 8 x 25 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 25 8 3-0 2 + 2 3-75
1	75180102	258 with 8 x 25 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 25 8 3-0 4 + 4 3-85
1	75200101	404 with 4 x 40 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 40 4 3-0 2 3-55
1	75200102	404 with 4 x 40 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 40 4 3-0 4 3-65
1	75200111 ¹	404 with 4 x 40 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 40 4 1-5 2 2-00
1	75220101	408 with 8 x 40 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 40 8 3-0 2 + 2 4-70
1	75220102	408 with 8 x 40 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 40 8 3-0 4 + 4 4-80
1	75220111 ²	408 with 8 x 40 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 40 8 1-5 1 + 1 2-50
1	75240101	634 with 4 x 63 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 63 4 3-0 2 + 2 4-70
1	75240102	634 with 4 x 63 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 63 4 3-0 4 + 4 4-80
1	75240111	634 with 4 x 63 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 63 4 1-5 1 + 1 2-50


1 : For use with both 25 and 40 A systems, and also 2 and 4 conductor versions
2 : For use with both 25 and 40 A systems, and also 6 and 8 conductor versions

LB PLUS straight lengths – Type B

straight lengths 25-63 A



75360102H

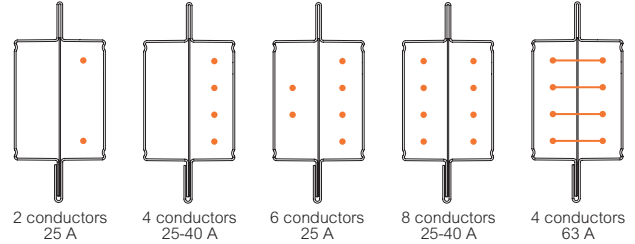

Selection chart p. 6-7
Technical data p. 13
Dimensions and technical information p. 14-15

Pack	Cat. Nos.	Straight lengths – Type B
		Reinforced highly rigid galvanised steel casing 7 m maximum distance between suspension brackets Conductors insulated with self-extinguishing plastic ZH (zero halogen) Standard tap-off outlets with captive IP 55 plug-outlet covers Mechanical separation of the 2 sides of the bar, (6 and 8 conductor versions) Protection index : IP 55 Impact resistance : IK 07
1	75350102H	252 with 2 x 25 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 25 2 3-0 4 5-45
1	75360102H	254 with 4 x 25 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 25 4 3-0 4 5-55
1	75360103H	254 with 4 x 25 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 25 4 3-0 6 5-60
1	75370101H	256 with 6 x 25 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 25 6 3-0 4 + 4 6-10
1	75380101H	258 with 8 x 25 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 25 8 3-0 4 + 4 6-20
1	75380102H	258 with 8 x 25 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 25 8 3-0 6 + 6 6-35
1	75400102H	404 with 4 x 40 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 40 4 3-0 4 6-00
1	75400103H	404 with 4 x 40 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 40 4 3-0 6 6-10
1	75400111H ¹	404 with 4 x 40 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 40 4 1-5 2 3-20
1	75420101H	408 with 8 x 40 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 40 8 3-0 4 + 4 7-10
1	75420102H	408 with 8 x 40 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 40 8 3-0 6 + 6 7-30
1	75420111H ²	408 with 8 x 40 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 40 8 1-5 1 + 1 3-70
1	75440101H	634 with 4 x 63 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 63 4 3-0 4 + 4 7-10
1	75440102H	634 with 4 x 63 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 63 4 3-0 6 + 6 7-30
1	75440111H	634 with 4 x 63 A conductors Rating (A) Conductors Length (m) Outlet points Weight (kg) 63 4 1-5 1 + 1 3-70

1 : For use with both 25 and 40 A systems, and also 2 and 4 conductor versions
2 : For use with both 25 and 40 A systems, and also 6 and 8 conductor versions