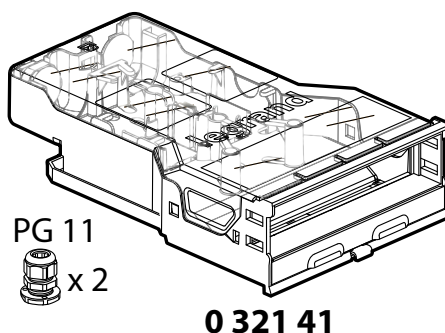


Splice cassettes for modular panels

Cat. No(s): 0 321 10/11/12/13/14/16/17/20/21/27/36/37/41 /
0 321 80/81/82/83/84/85/86/87 / 0 322 58/HVBL12



PG 11
x 2

0 321 41

 
 
1. PRESENTATION

Fibre optic splice cassettes

 
Splice cassettes supplied with a removable pigtail holder and cable coiling area. Cable coiling can be achieved using cable glands (supplied with 2 PG11) or a fan-out.

Compatible with all modular fibre blocks and high-density MTP adapters. For installation in modular panels Cat. Nos. 0 321 75/76/77.

2. RANGE

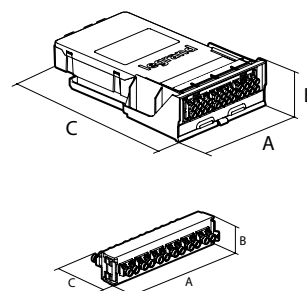
	0 321 41	Splice cassette
	0 321 11 SC duplex HD 12 singlemode fibres 0 321 21 SC duplex HD 12 multimode fibres 0 321 10 SC duplex 6 singlemode fibres 0 321 12 SC apc duplex 6 singlemode fibres 0 321 20 SC duplex 6 multimode fibres 0 321 13 LC duplex 6 singlemode fibres 0 321 36 LC duplex 6 multimode fibres (aqua) 0 321 14 LC duplex 12 singlemode fibres 0 321 16 LC apc duplex 12 singlemode fibres 0 321 37 LC duplex 12 multimode fibres (aqua) 0 322 58 LC duplex 12 multimode fibres (lime) - HVBL12 LC duplex 12 multimode fibres (violet) 0 321 17 ST for 6 singlemode fibres 0 321 27 ST for 6 multimode fibres	
		Singlemode red cap
		Multimode black cap

Splice cassettes - supplied with pigtails and blocks

	0 321 80	Spliceable FO cassette 0 321 41 + SC block for 6 multimode fibres 0 321 20 + 6 OM3 SC pigtails 1m 0 322 20
	0 321 82	Spliceable FO cassette 0 321 41 + SC block for 12 multimode fibres 0 321 21 + 12 OM3 SC pigtail 1m 0 322 20
	0 321 84	Spliceable FO cassette 0 321 41 + SC block for 6 singlemode fibres 0 321 10 + 6 OS2 SC pigtails 1m 0 322 41
	0 321 86	Spliceable FO cassette 0 321 41 + SC block for 12 singlemode fibres 0 321 11 + 12 OS2 SC pigtail 1m 0 322 41
	0 321 81	Spliceable FO cassette 0 321 41 + LC block for 6 multimode fibres 0 321 23 + 6 OM3 LC pigtails 1m 0 322 21
	0 321 83	Spliceable FO cassette 0 321 41 + LC block for 12 multimode fibres 0 321 24 + 12 OM3 LC pigtail 1m 0 322 21
	0 321 85	Spliceable FO cassette 0 321 41 + LC block for 6 singlemode fibres 0 321 13 + 6 OS2 LC pigtails 1m 0 322 43
	0 321 87	Spliceable FO cassette 0 321 41 + LC block for 12 singlemode fibres 0 321 14 + 12 OS2 LC pigtail 1m 0 322 43

3. DIMENSIONS (mm)

Cat. Nos.	A	B	C
0 321 41/80/81/82 0321 83/84/85/86/87	110	44	185
0 321 10/11/12/20/21	109	23	33
0 321 13/14/16/36/37/0 322 58/HVBL12			39
0 321 17/27			45



4. CASSETTE AND BLOCK WEIGHT (g)

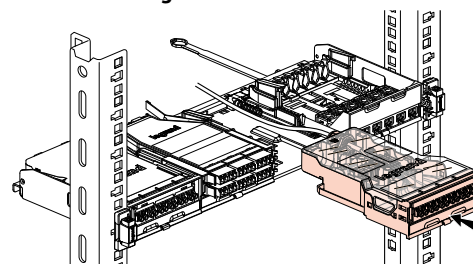
Cat. Nos.	Weight
0 321 41/80/81/82 0321 83/84/85/86/87	195
0 321 10/11/12/13/14/16/17/20/21/27/36/37 0 322 58/HVBL12	50

5. CASSETTE TECHNICAL CHARACTERISTICS

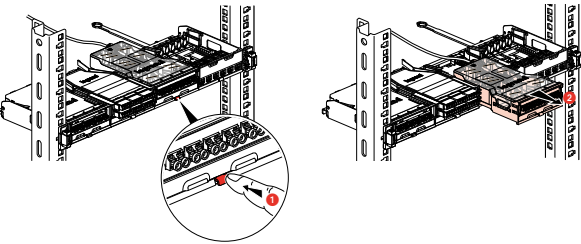
5.1 Material characteristics

Polycarbonate
IP40

5.2 Cassette mounting



5.3 Cassette removal

 
 
 
 
 
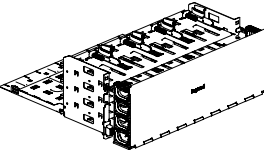
 
 


5.4 Storage and operating temperature
- 10° C to + 60° C

6. ON-DEMAND SOLUTION

Please contact your Legrand sales representative.

7. COMPATIBILITY

Panels		Splice cassette	Blocks for splice cassette							
			SM Blue	SM APC Green	MM Aqua	MM Violet	MM Beige	MM Lime		
Base 12	032175 	032141 	12 fibres	LC 	032114	032116	032137	HVBL12	-	032258
	SC 			032111	-	-	-	032121	-	
	032176 	6 fibres	LC 	032113	-	032136	-	-	-	
	032177 		SC 	032110	032112	-	-	032120	-	
				SM red cap		MM black cap				
			ST 	032117		032127				