


0 340 30/31/32/33/34

0 340 41/42/43/44/45




0 340 30/31/32/33/34

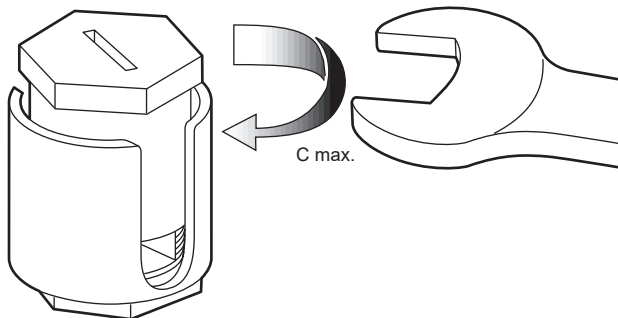

Réf.	C max.
0 340 30	3,4 Nm
0 340 31	1,1 Nm
0 340 32	4,3 Nm
0 340 33	5,2 Nm
0 340 34	9,1 Nm

0 340 41/42/43/44/45

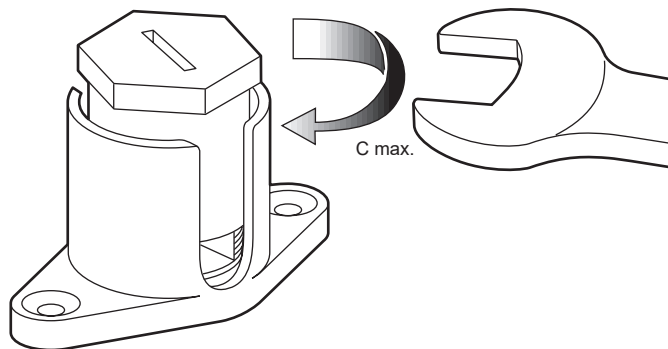

Réf.	C max.
0 340 41	1,1 Nm
0 340 42	4,3 Nm
0 340 43	5,2 Nm
0 340 44	9,1 Nm
0 340 45	12,1 Nm