


Arteor™

Ref . No. : 572074 / 572574

DND & CMR Internal Unit

Date : 19/01/2024

Rev.1

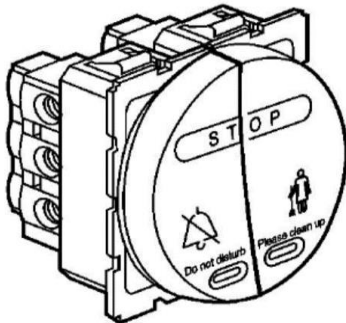

1. USE

For hospitality / hotel function and accessories for indication purpose.

2.Type

Two way switch single pole
 No. of modules : 1+1
 Colour : White / Magnesium
 Mounting : Flush and Surface -mounted

3.OVERALL DIMENSIONS

Width : 22.5 mm+ 22.5mm
 Height : 45.1 mm+ 45.1mm
 Depth : 37.8 mm + 37.8mm
 Weight (g) : 49

4.CONNECTION

Terminals : with screws
 Capacity: 1.5 mm² to 4 mm²
 Stripping :10mm
 Screwdriver : 4mm flat-blade upto 5mm

For wiring connection and product installation refer instruction sheet LE01561AC.

5.OPERATION

Switch with Rocker

6.TECHNICAL CHARACTERISTICS

6.1 Material Characteristics

Rocker : Polycarbonate
 Base : Polycarbonate
 Contact Terminal : Brass
 Pivot Terminal : Brass
 Screws : Steel with Zinc plating
 Rocker spring : Stainless steel
 Transmitter : Polypropylene
 Plunger: Polycarbonate
 Contact Tip : Silver
 Moving Contact : Brass

Voltage			Audible signal
230 V 50 Hz	2 x 2.5 mm ²	- 5° C + 40° C	230 V / 33 mA 72 dB

6.2 Electricals Characteristics

Voltage : 230V AC
 Current : 6A
 Self - extinguishing : 850° C / 30 s.

7.CONFORMITY - APPROVALS

As per Company Standard